


Dimensions: mm (in.)

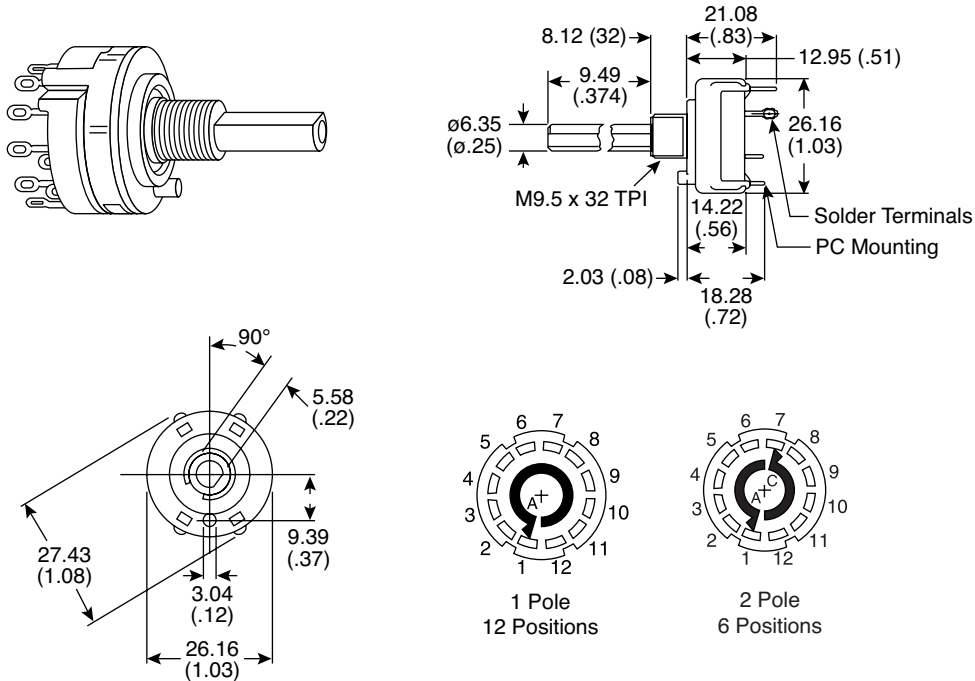

Electrical Specifications:

- Maximum working voltage: 250VAC/DC resistive load
- Proof voltage: 1,000 RMS min.
- Current carrying capacity: 5A (non-switching)
- Contact rating: 150mA/250VAC/DC
- Insulation resistance: 25,000M Ω min.
- Contact resistance: 50m Ω min.

Lorlin Part No.	Poles	Pos. NS (max.)	SL (In)
CK2403	1	12	3/8
CK2407	2	6	3/8
CK2405	2	6	1/2
CK1121	2	6	1 3/16

Mechanical Specifications:

- Operating temperature: -30°C to +85°C
- Life: greater than 10,000 cycles
- Operating torque (nominal): 8.6 Ncm $\pm$ 1 Ncm
- End stop torque (minimum): 0.80 Nm

Materials:

- Moulding: glass filled nylon
- Contact / terminal: silver plated brass
- Solder Terminals

Rotary Switches

CK2403, CK2407, CK2405, CK1121

Available from Mouser Electronics

1-800-346-6873

www.mouser.com

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.