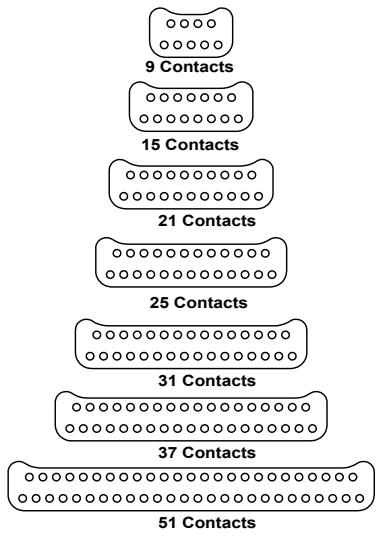


MIL-DTL-32139 Nanominiature Connectors

Dual Row Metal Shell Pigtails (M32139/03 & /04)

How to Order

How To Order M32139 Dual Row Metal Shell Connectors

Basic Spec	Slash Number - Insert Arrangement	Wire Type	Hardware	Shell Material and Finish	Space Class
M32139/ Note: order with "GS" prefix until QPL approval is issued. GS32139/	Plugs 03-A – Pin Connector, 9 Contacts 03-B – Pin Connector, 15 Contacts 03-C – Pin Connector, 21 Contacts 03-D – Pin Connector, 25 Contacts 03-E – Pin Connector, 31 Contacts 03-F – Pin Connector, 37 Contacts 03-G – Pin Connector, 51 Contacts Receptacles 04-A – Socket Connector, 9 Contacts 04-B – Socket Connector, 15 Contacts 04-C – Socket Connector, 21 Contacts 04-D – Socket Connector, 25 Contacts 04-E – Socket Connector, 31 Contacts 04-F – Socket Connector, 37 Contacts 04-G – Socket Connector, 51 Contacts	NEMA HP3-ETXBBB Wire (#30 AWG, 7 Strand Silver-Coated Copper, Extruded PTFE Insulation, 250 V rms, 200° C.) 01 – 6 Inches White 02 – 18 Inches White 03 – 36 Inches White 04 – 6 Inches 10 Color Repeat 05 – 18 Inches 10 Color Repeat 06 – 36 Inches 10 Color Repeat M22759/33-30 Wire (#30 AWG, 7 Strand Silver-Coated High-Strength Copper, Extruded Cross-Linked Modified ETFE Insulation, 600 V rms, 200° C.) 07 – 6 Inches White 08 – 18 Inches White 09 – 36 Inches White 10 – 6 Inches 10 Color Repeat 11 – 18 Inches 10 Color Repeat 12 – 36 Inches 10 Color Repeat Composite PTFE/ Polyimide Wire (#30 AWG, 7 Strand Silver-Coated High-Strength Copper, Tape-Wrapped Dual-wall Modified ETFE/Polyimide Insulation, 600 V rms, 200° C.) 13 – 6 Inches White 14 – 18 Inches White 15 – 36 Inches White 16 – 6 Inches 10 Color Repeat 17 – 18 Inches 10 Color Repeat 18 – 36 Inches 10 Color Repeat	S Jackscrew, #0-80, Hex Head (Slash 01 Pin Connectors Only) T Threaded Hole, #0-80 (Slash 02 Socket Connectors Only)	C Aluminum Shell, Cadmium Plated N Aluminum Shell, Electroless Nickel Plated S Stainless Steel Shell, Passivated T Titanium Shell, Unplated	S Space Class (Not For Use With Cadmium Plated Aluminum Shells) Omit for Non-Space Applications
					

Part Number Example

M32139/

03-A

01

S

N

S

Glennair®