

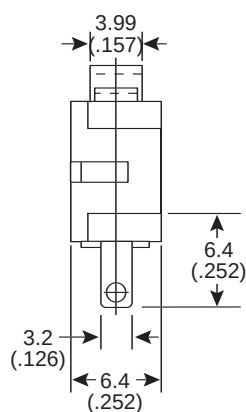
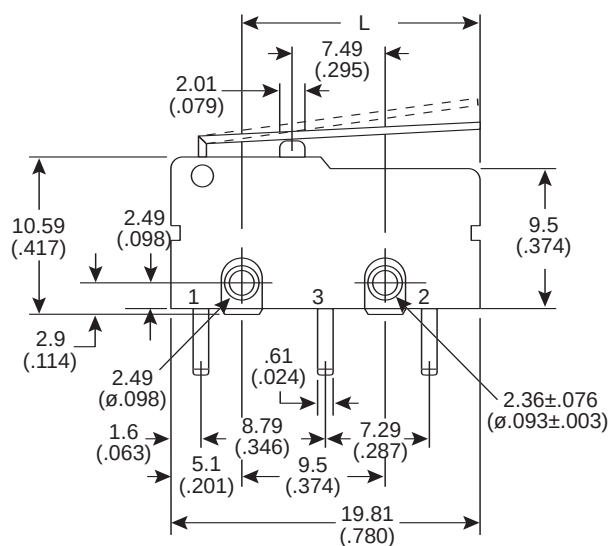
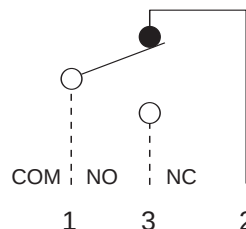


Dimensions:mm (In.)

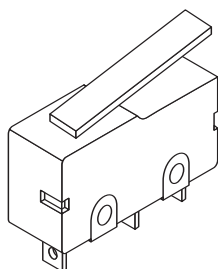

Solder Lug

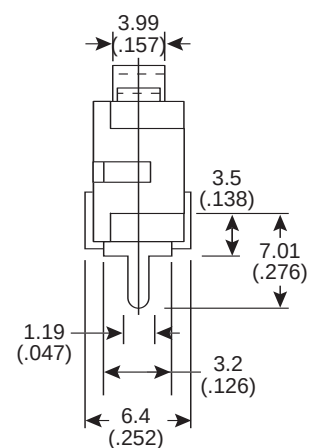

* PC Pin

Electrical Specifications:

- Rating: 5A/125VAC
- Insulation resistance: 100MΩ > 500VDC
- Dielectric strength: 500VAC for 1 minute
- Contact resistance: <50mΩ
- Life cycling (full load): 200,000 cycles

Mechanical Specifications:

- Switching timing: non-shorting
- Life cycling (no load): 1,000,000 cycles
- Operating temperature: -25°C ~ +80°C

Mouser Stock No.	L (In.)	Travel (In.)	Oper. Force	Terminal Type
101-1201	.571	.079	28g	Solder Lug
101-1202	.650	.087	25g	Solder Lug
101-1203	.890	.126	18g	PC Pin
101-1206	1.69	.224	10g	PC Pin

Miniature Snap Switches

101-1201, 101-1202, 101-1203, 101-1206