




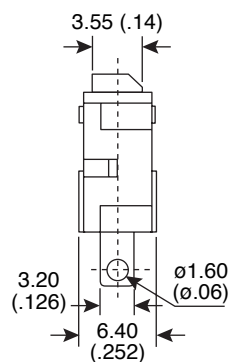

## Contact Configuration

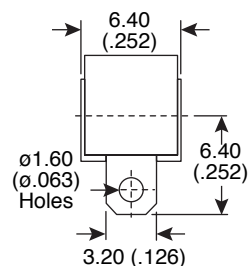

## Mounting Holes

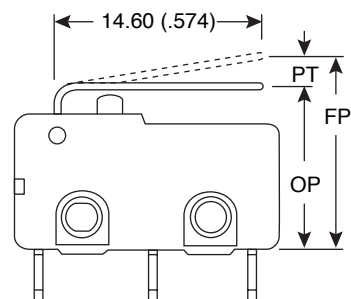

Solder Terminal

- Operating Frequency: 120 operations/min
- Life: 10,000,000 operation min.

- RoHS Compliant and process compatible with 260° solder

- Operating Frequency: 10~30 operations/min
- Life: 6,000~100,000 operations
- Rating: 5A/125VAC/250VAC
- Contact Resistance: 30mΩ max.
- Insulation Resistance: 100MΩ min. @ 500VDC
- Dielectric Strength: 1,000VAC RMS (50-60HZ)

- OF Max. (g): 25
- Op (mm): 11.8 ±0.8
- PT Max. (mm): 3.6
- OT Min. (mm): 0.6
- MD Max. (mm): 0.8
- FP Max. (mm): 14.6
- RF Min. (g): 6

# Mountain Switch

1-800-346-6873