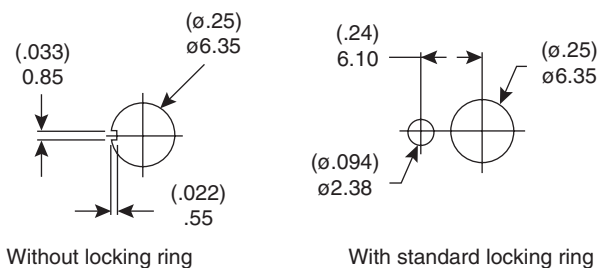
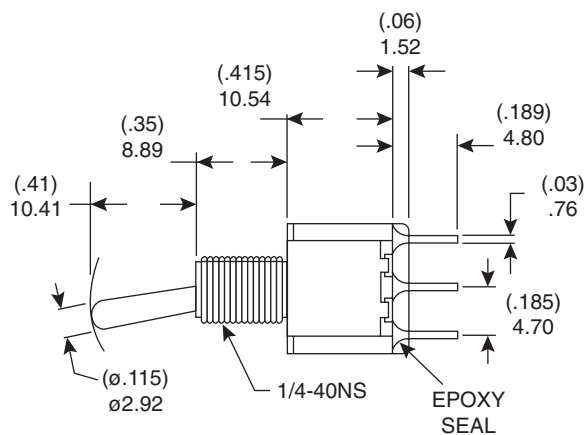
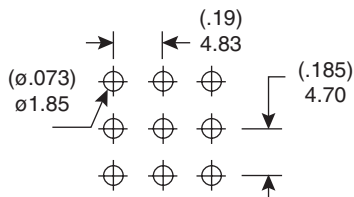
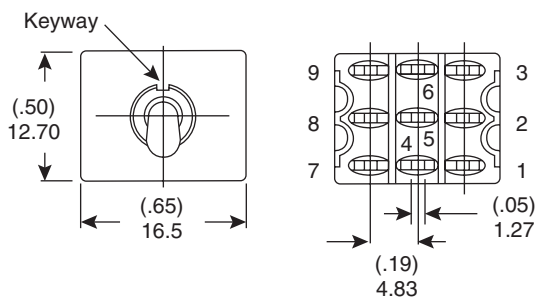


DIMENSIONS: mm (in.)**PANEL MOUNTING****P.C. MOUNTING**

Pos. 1	Pos. 2
ON	ON
2-3, 5-6, 8-9	2-1, 5-4, 8-7
1 2 Comm. 3 4 5 Comm. 6 7 8 Comm. 9	1 2 Comm. 3 4 5 Comm. 6 7 8 Comm. 9

SWITCH FUNCTION**Mechanical Specifications:**

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS @ sea level
- Rating: 2A/250VAC; 5A/120VAC or 28VDC

Mechanical Specifications:

- Operating Temperature: -30°C to +85°C

Note:

- RoHS compliant by exemption

Materials:

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Terminal/Contact: Silver or Gold plated

Toggle Switch
108-1M31T1B1M2QE-EVX

Mountain
Switch