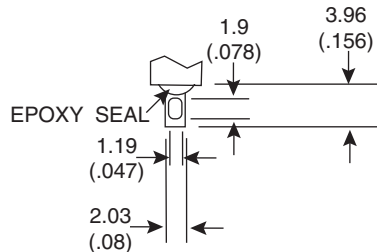
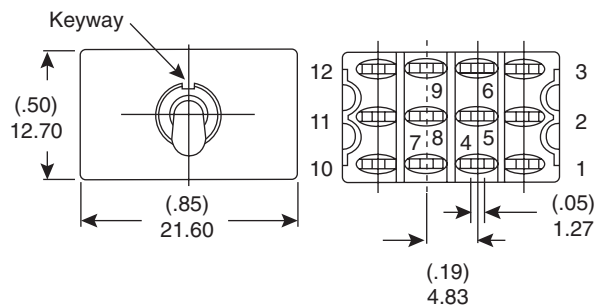
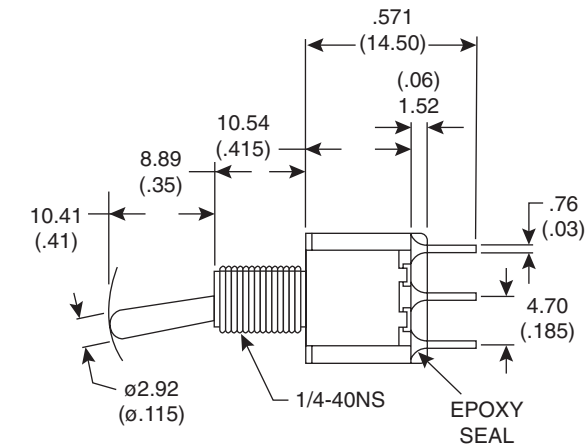
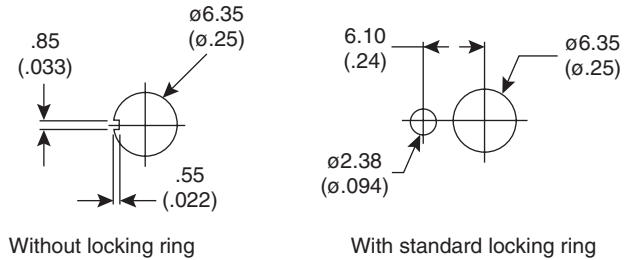


**DIMENSIONS: mm (in.)****SOLDER LUG****PANEL MOUNTING**

| Pos. 1               | Pos. 2               |
|----------------------|----------------------|
|                      |                      |
| ON                   | ON                   |
| 2-3, 5-6, 8-9, 11-12 | 2-1, 5-4, 8-7, 11-10 |
|                      |                      |

**SWITCH FUNCTION****Electrical Specifications:**

- Electrical Life: 40,000 make-and-break cycles at full load
- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS@ sea level
- Rating: 2A/250VAC; 5A/120VAC or 28VDC

**Mechanical Specifications:**

- Operating Temperature: -30°C to +85°C

**Note:**

- RoHS compliant by exemption

**Materials:**

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Terminal/Contact: Silver or gold plated

**Toggle Switch**  
108-1M41T1B1M1QE-EVX

**Mountain**  
**Switch**