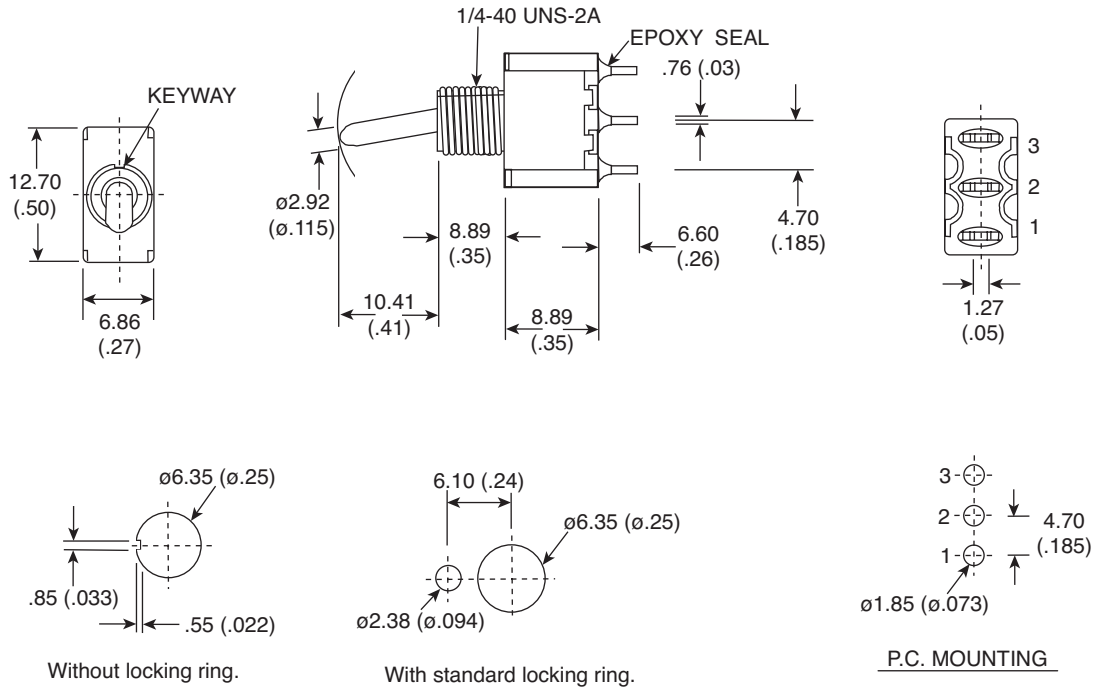


Dimensions: mm (in.)

PANEL MOUNTINGP.C. MOUNTING

POS.1	POS.2	POS.3
ON	NONE	ON
2-3	OPEN	2-1

SWITCH FUNCTION**Electrical Specifications:**

- Contact Resistance: 10m Ω max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Rating: 2A / 250 VAC, 5A / 120 VAC or 28 VDC
- Dielectric Strength: 1,000 V RMS@ sea level.

Mechanical Specifications:

- Operating Temperature: -30° C to +85° C

Note:

- RoHS Compliant by Exemption

Materials:

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated.
- Bushing: Brass, nickel plated.
- Housing: Stainless steel.
- Terminal/Contact: Silver plated.

Toggle Switch
108-1MS1T1B1M2QE-EVX

Mountain
Switch