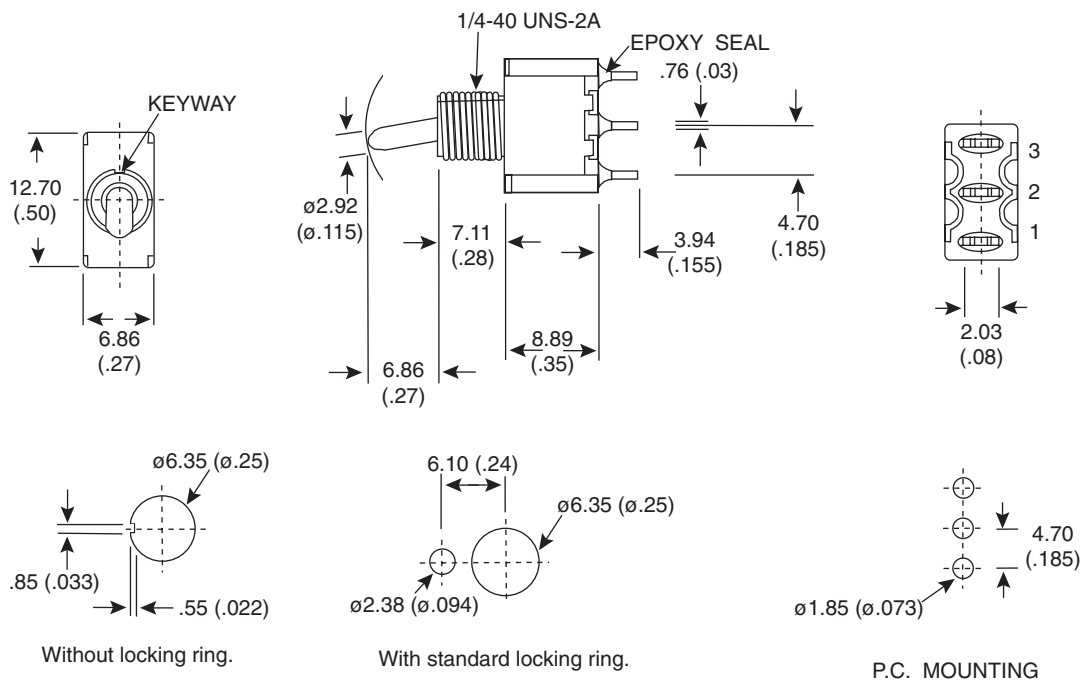


**DIMENSIONS: mm (in.)**

POS.1	POS.2
ON	ON
2-3	2-1

SWITCH FUNCTION

**Electrical Specifications:**

- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Rating: 2A / 250 VAC; 5A / 120 VAC or 28 VDC
- Dielectric Strength: 1,000 V RMS@ sea level

**Mechanical Specifications:**

- Operating Temperature: -30°C to +85°C

**Note:**

- RoHS Compliant by Exemption

**Materials:**

- Case: Diallyl phthalate (DAP)
- Acuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Terminal/Contact: Silver plated

**Toggle Switch**  
108-1MS1T2B3M2QE-EVX

**Mountain**  
**Switch**