
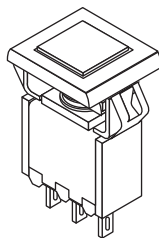


## Dimensions: mm (in.)

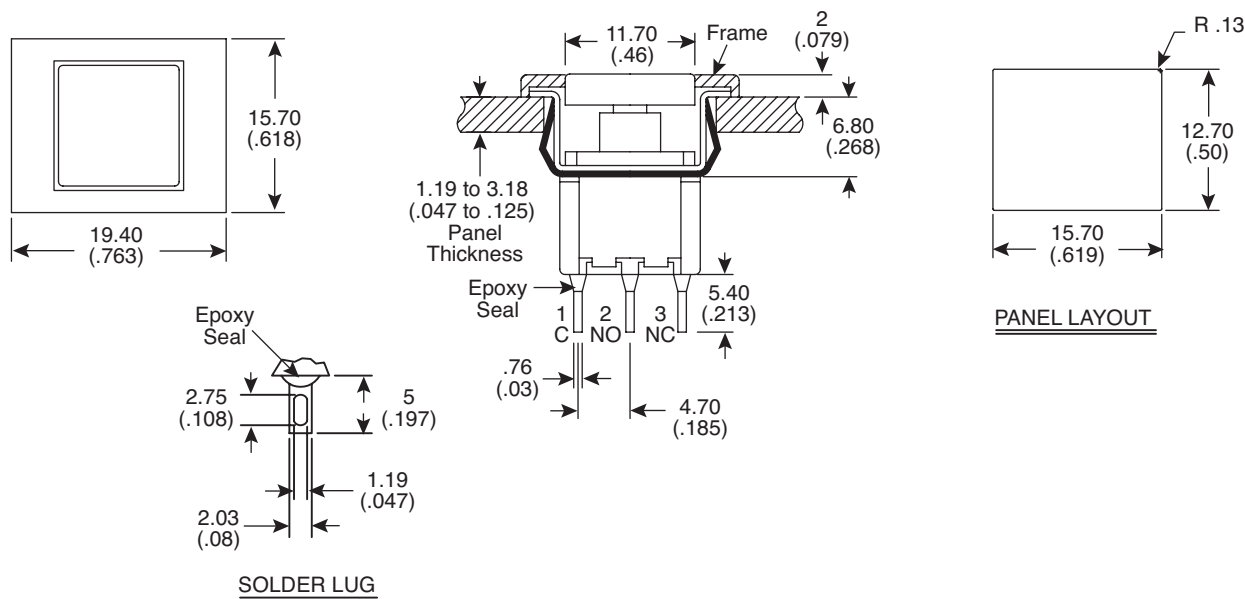

| POS. 1 | POS. 2 |
|--------|--------|
|        |        |
| ON     | MOM    |
| 1-3    | 1-2    |
|        |        |

SWITCH FUNCTION**Electrical Specifications:**

- Rating: 1A/250VAC, 3A/120VAC or 28 VDC
- Contact Resistance: 20mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Dielectric Strength: 1,000 V RMS@ sea level

**Materials:**

- Case: Diallyl phthalate (DAP)
- Plunger: Glass filled nylon or glass filled polyester
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Contact: Silver plated

**Mechanical Specifications:**

- Mechanical Life: 50,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

**Note:**

- RoHS compliant by exemption

**Snap-Acting Pushbutton Switch**  
107-3008-EVX

**Mountain**  
**Switch**