

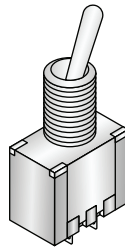


Dimensions: mm (in.)

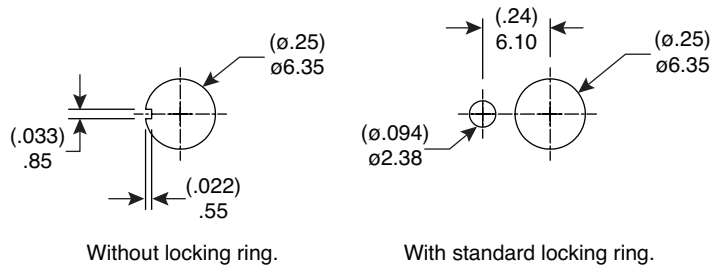


| POS. 1 | POS. 2 |
|--------|--------|
| | |
| ON | OFF |
| 2-3 | OPEN |
| | |

SWITCH FUNCTION

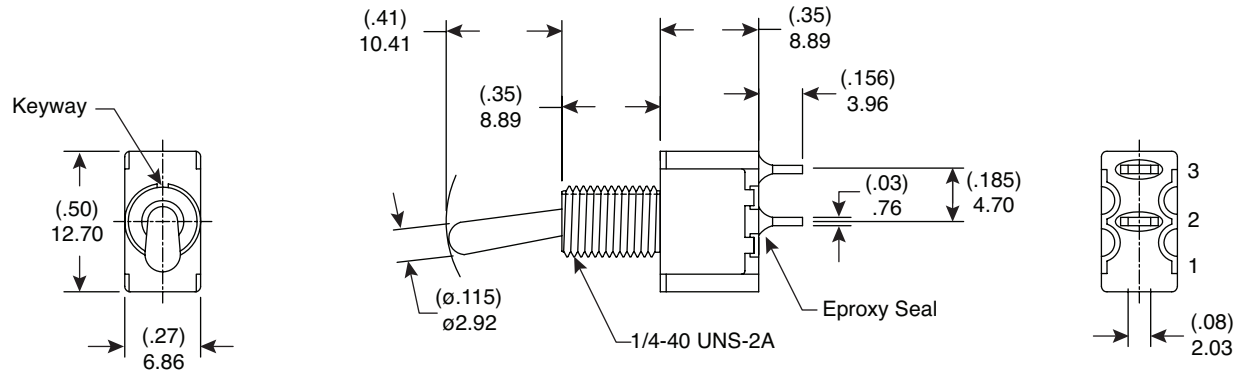

Panel Mounting

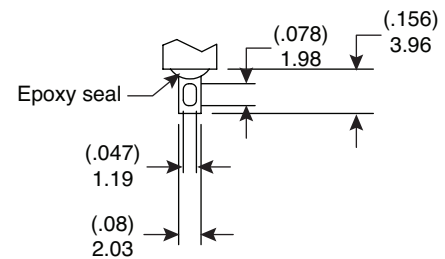

Solder Lug

Electrical Specifications:

- Rating: 2A / 250VAC, 5A / 120 VAC or 28 VDC
- Contact Resistance: 10m Ω max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000M Ω min.
- Dielectric Strength: 1,000 V RMS@sea level

Mechanical Specifications:

- Mechanical Life: 40,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C
- Type: SPST
- Circuit: On-Off

Materials:

- Case: Diallyl phthalate (DAP)
- Actuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless Steel
- Terminal/Contact: Silver or gold plated

Note:

- RoHS compliant by exemption

Miniature Toggle Switch
108-0001-EVX

Mountain
Switch