

PP2 SERIES PUSHBUTTON SWITCH


ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS



APPLICATIONS / MARKETS



Commercial Appliances

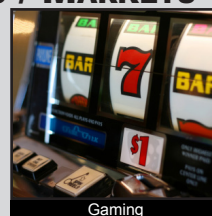

Gaming



HVAC



Security Devices



RoHS

SPECIFICATIONS

Electrical Rating:

Rating Option 1: 10R (4)A 277VAC 5E4

Rating Option 7: 16A 125VAC [cURus];

12A 250VAC [cURus]; 1HP 125/250VAC [cURus]

Electrical Life: 6,000 Cycles

Mechanical Life: 50,000 Cycles

Contact Resistance: 10mΩ Max.

Insulation Resistance: 100MΩ Min.

Operating Temperature 0°C to 85°C

Panel Cutout: 13.5mm x 36mm

Function: DPDT, On-(On) or On₁-On₂-(On₁)

FEATURES & BENEFITS

- Push-pull or momentary functions
- Various actuator and terminal options
- High ratings with UL approvals
- Acts as door interlock switch

PART NUMBER CONFIGURATOR

Series	Terminal Type	Function	Rating	Body Color	Actuator Height	Actuator Color
PP2	1 - 4.8mm x 0.8mm Tabs, Vertical 4 - 6.3mm x 0.8mm Tabs, Vertical 7 - 4.8mm x 0.5mm Tabs, Vertical	H - On-On U - On ₁ -On ₂ -(On ₁)	1- 10R(4)A 277VAC 5E4 7 - 16A 125VAC 12A 250VAC 1HP 125/250VAC	1 - Black 2 - White	*A - 21.7mm Straight **B - 18.3mm Push-Pull **C - 20.8mm Push-Pull *D - 11.4mm Short	2 - White

* Available with "H" function only

** Available with "U" function only

Specifications subject to change without notice



E-SWITCH®




www.e-switch.com

800.867.2717

42


PP2 SERIES PUSHBUTTON SWITCH

STANDARD BODY DIMENSIONS

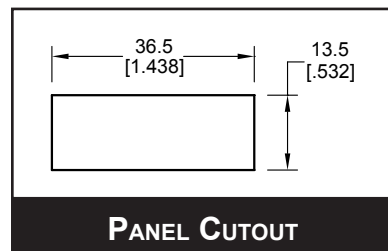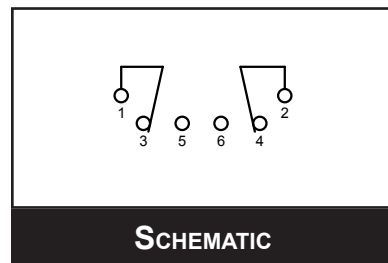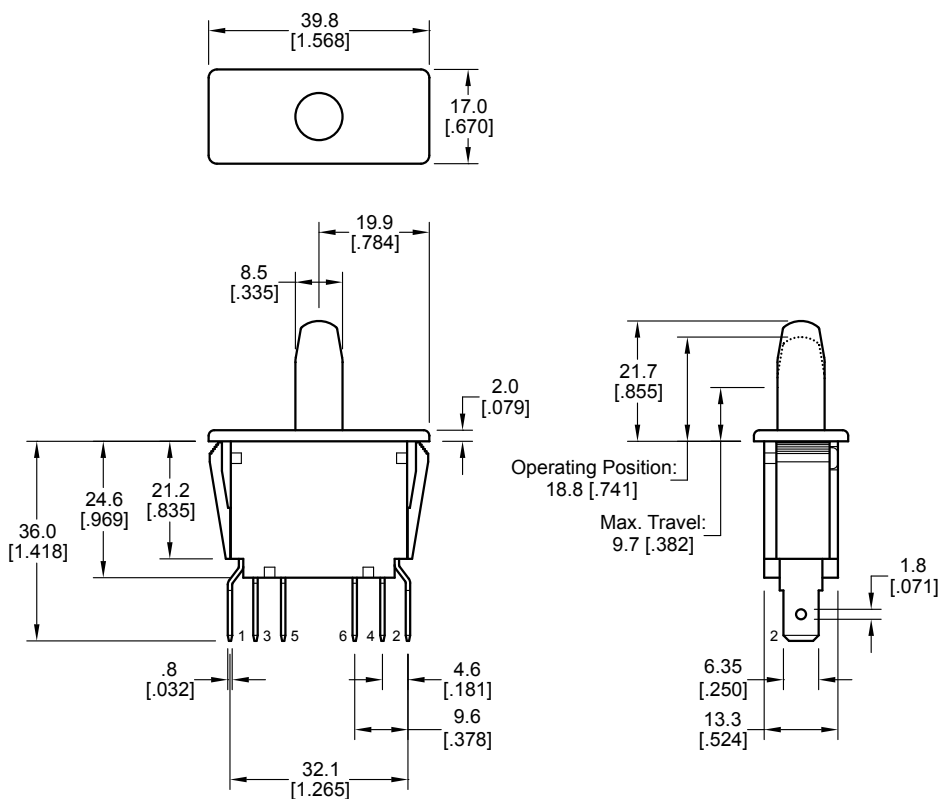

LONG BODY DIMENSIONS

Available with "C" actuator only

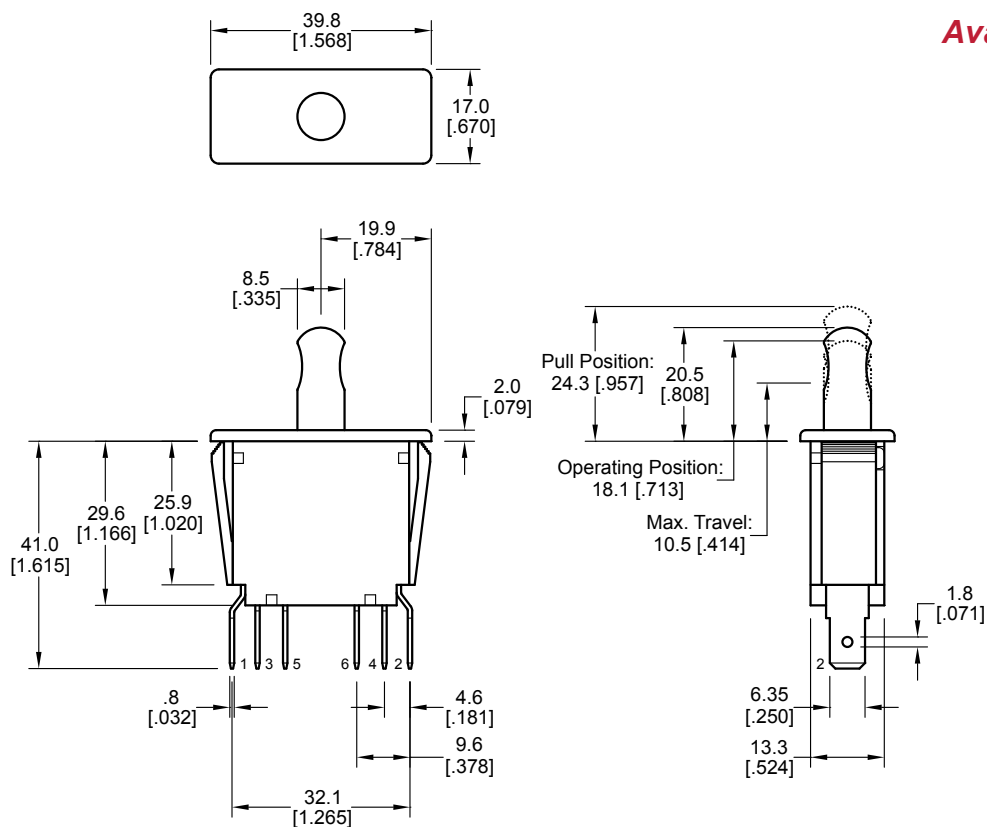

E-SWITCH®




www.e-switch.com

800.867.2717

43

ANTI-VANDAL SWITCHES
DETECTOR SWITCHES
DIP SWITCHES
KEYLOCK SWITCHES
NAVIGATION SWITCHES
PUSHBUTTON SWITCHES
ROCKER SWITCHES
ROTARY SWITCHES
SLIDE SWITCHES
SNAP ACTION SWITCHES
TACTILE SWITCHES
TOGGLE SWITCHES
CAP OPTIONS

TERMINAL OPTIONS

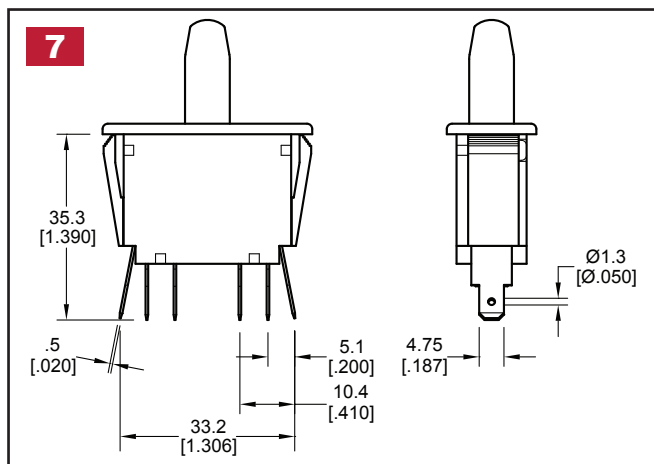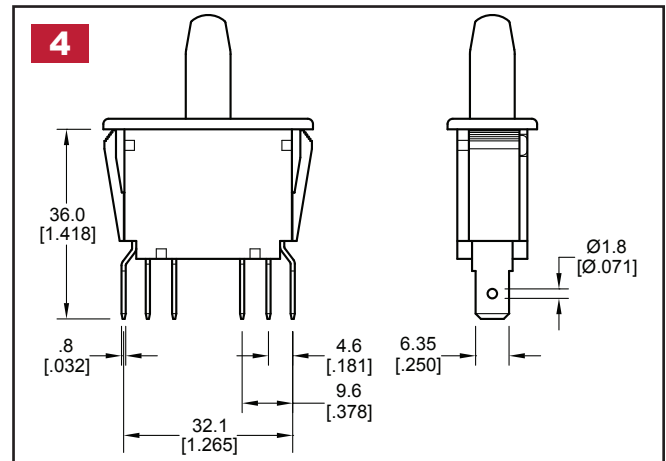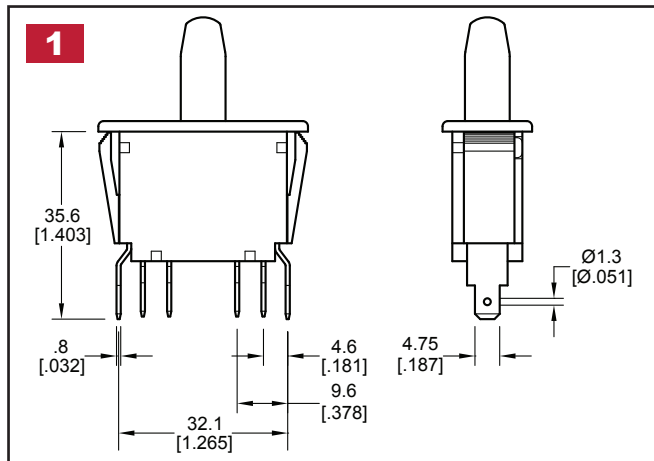

ACTUATOR OPTIONS

