
 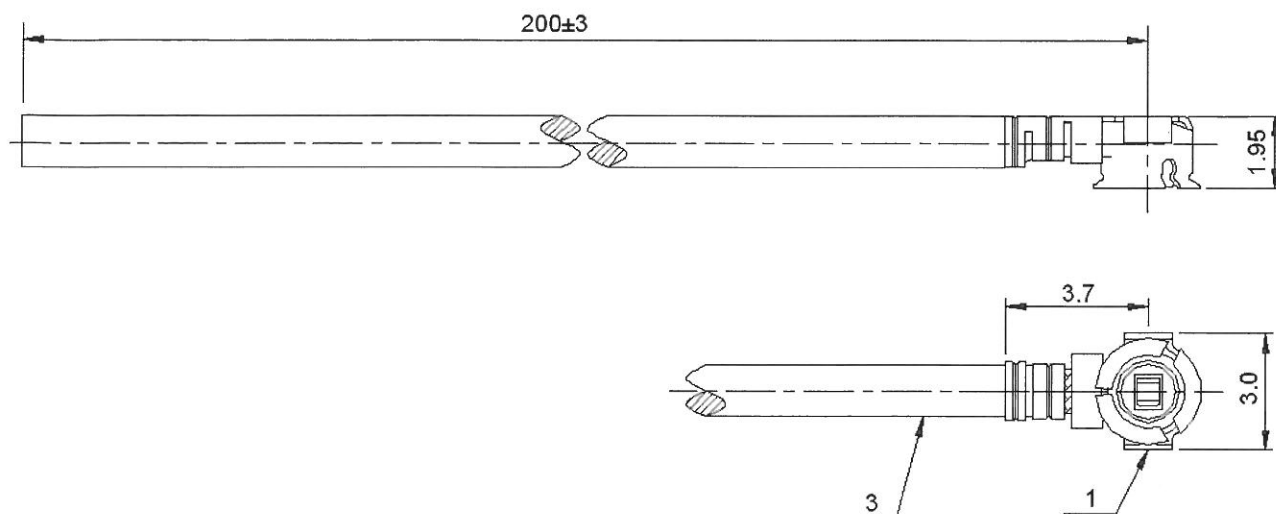


PLUG MML H2.5- PIGTAIL**R302.255.003****CABLE 1.33/50S-BR,LENGTH 20CM****Series : MML**

All dimensions are in mm.



- * 1 * Connector A : **MML H2.5 PLUG (gold plated)**
- * 2 * Connector B : **NA**
- * 3 * Cable : **1.33/50S BLACK**

ELECTRICAL CHARACTERISTICS**SPECIFICATION**

Impedance	50 Ω
Frequency	0-3 GHz
Operating temperature	-40/+90 ° C
VSWR	NA + 0.000 x F(GHz) Maxi
Insertion loss	NA $\sqrt{F}$(GHz) dB Maxi
Voltage rating	250 Veff Maxi
Dielectric withstanding	300 Veff mini
Insulation resistance	500 MΩ mini

Weight	0.8600 g
Cable retention	4 N mini
Mating life	30 Cycles
Others :	