

P/N

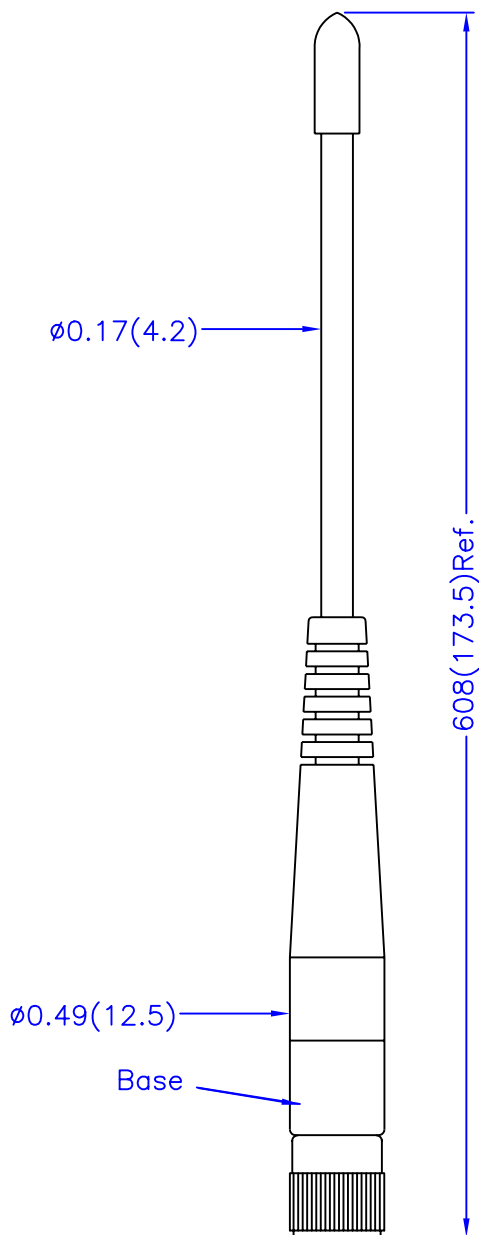
S161AM-915

Alternative Connectors*.SMA Reverse Polarity Plug(female)*

P/N: S161AH-915

.SMA Reverse Thread Plug(male)

P/N: S161AT-915

Electrical Properties:

Frequency Range: 902~928 MHz
Impedance: 50Ω nominal
VSWR: <2.0:1
Gain: 2.5 dBi
Radiation: Omni
Polarization: Vertical
Wave: ½wave loaded

Mechanical Properties:

Connector: SMA Plug
Material:
Whip: Wire (Black)
Base: Polyacetal(Black)
Connector: Brass with nickel plating(Black)
Operation Temp.: -20°C to +65°C
Storage Temp.: -30°C to +75°C

TOLERANCE		TITLE	900MHz ISM Band Antenna-161 Model		DATE	SHEET
.X						1 OF 1
.XX		UNIT	DWG. NO.	S161AM-915	A4	
.XXX		in.(mm)				
		SCALE				
ANGLE		1 : 1				

NEARSON