




Rotary Switch 105-SR2513F-112NS

Dimensions: mm (in)

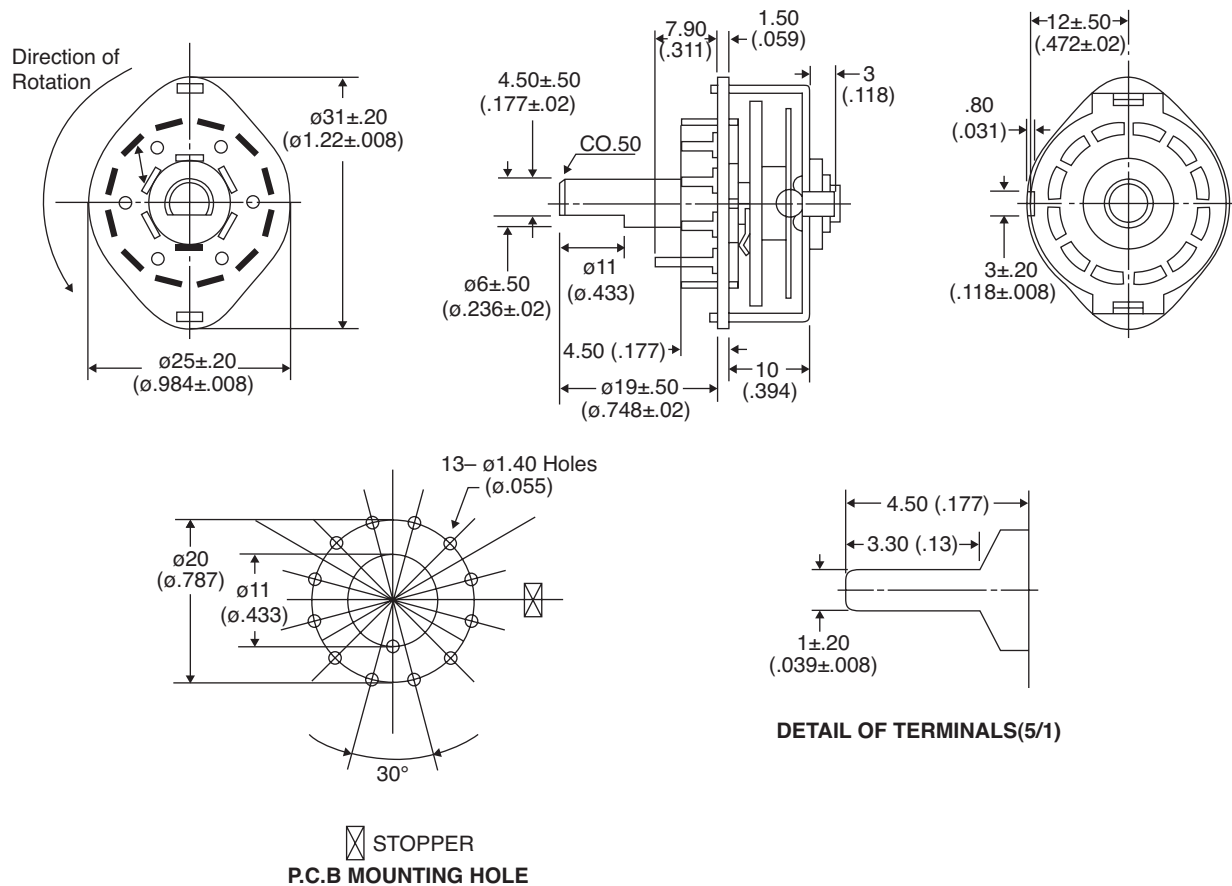

Electrical Specifications:

- Rating: 0.3A/125VAC
- Contact Resistance: 50 mΩ Max.
- Insulation Resistance: 500VDC–100MΩ Min.
- Dielectric Strength: 500VAC– 1 Minute

Mechanical Specifications:

- Rotation Torque: 1.0 ±0.5 Kg - cm
- Timing: Non-Shorting
- Termination: PC Mount
- Poles: 1
- Positions: 12

Note:

- RoHS Compliant