




Rotary Switches

105-SR2511F-25NS, 105-SR2511F-26RN,
105-SR2511F-34NS, 105-SR2511F-43RN,
105-SR2511F-62RN, 105-SR2511F-12RN

Dimensions: mm (in)

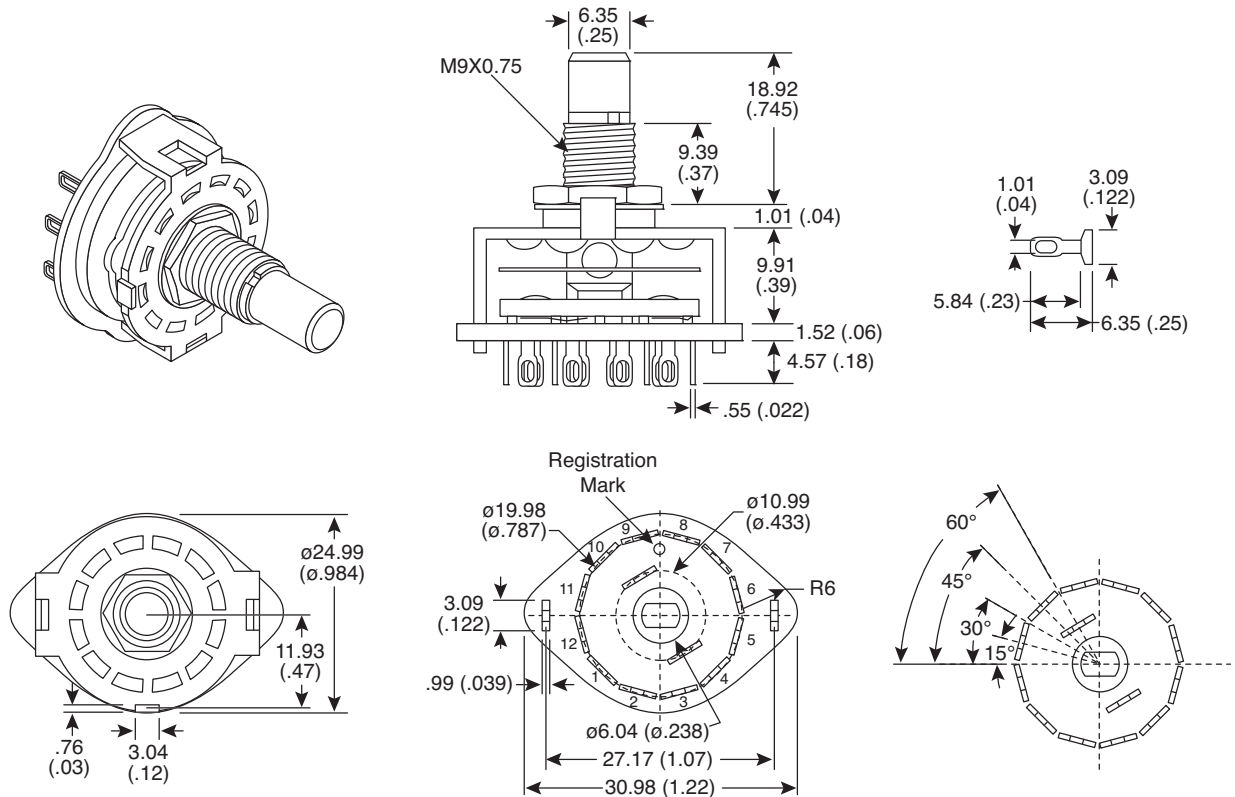

Electrical Specifications:

- Rating: 0.3A/125VAC
- Contact resistance: 30mΩ max. 1A
- Insulation resistance: 10MΩ @ 500VDC min.
- Dielectric strength: 500VAC for 1 minute

Mechanical Specifications:

- Type: non-shorting contact (break before make)
- Rotation torque: 1~3KG/cm

Materials:

- Hardware included: 1 hexagon nut & 2 washers
- Shaft: 1/4"

Note:

- RoHS Compliant

Mouser Stock No.	Poles	Position
105-SR2511F-25NS	2	5
105-SR2511F-26RN	2	6
105-SR2511F-34NS	3	4
105-SR2511F-43RN	4	3
105-SR2511F-62RN	6	2
105-SR2511F-12RN	1	12