





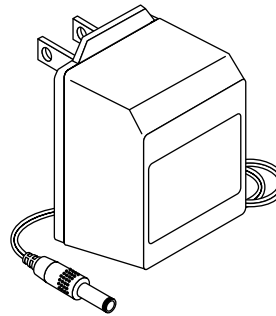


AC Adapter 12VDC/300mA

412-112034

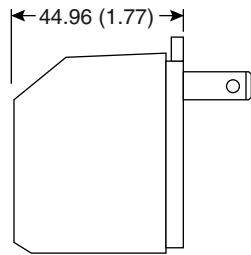

DIMENSIONS: mm (in.)

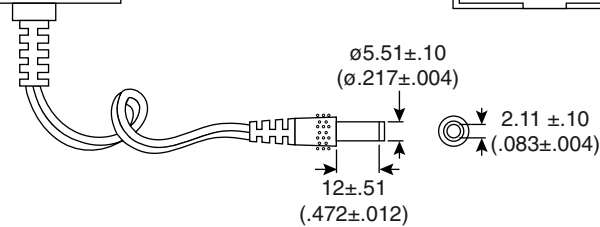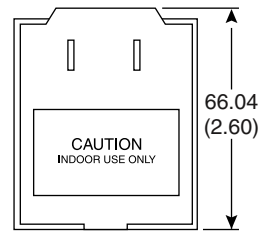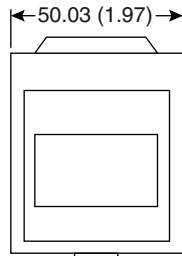

■ SPECIFICATIONS

- Primary voltage: 120VAC 60Hz
- Secondary, no load voltage: 15.6VDC \pm 5%
- Loaded voltage: 12VDC @ 300mA \pm 5%
- Insulation resistance: primary-secondary: 100M Ω @ 500VDC
- Dielectric strength: primary-secondary: 1500 VAC 2mA 1 minute

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

