


# KEMET Part Number: ELG157M400AQ3AA



Capacitor, aluminum, 150 uF, +/-20% Tol, -25/+105C, 400VDC@ rated temp

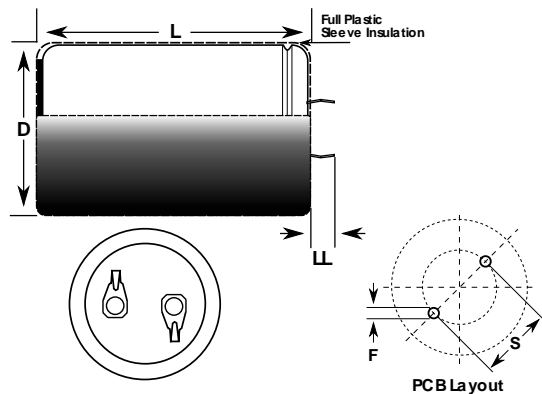

## Dimensions (mm)

Symbol	Dimension	Tolerance
D	22	+/-1
L	35	+/-2
S	10	+/-0.5
LL	5.8	+/-1
F	2	+/-0.1

## Packaging Specifications

Package Kind:	Bulk
---------------	------

## General Information

Supplier:	KEMET
Part Type Description:	Snap-In Aluminum Electrolytic
Lead Type:	2 Pin

## Specifications

Capacitance:	150 uF
Tolerance:	+/-20%
Voltage @ rated temp:	400VDC
VDC Surge:	450VDC
Life @ rated temp:	2000 Hrs
RoHS:	Yes
Low Z/ESR:	Yes
Temperature Range:	-25/+105C
ESR at 20kHz @ room temp:	388 mOhm
Leakage Current:	1.2 mA
Leakage Condition:	5min/20c
Dissipation Factor:	15%
Ripple 120Hz @ rated temp:	0.8 A