


# Product data sheet

## Characteristics

### XZCP1241L10

pre-wired connectors XZ - elbowed female - M12 - 4 pins - cable PUR 10m

Product availability: Non-Stock - Not normally stocked in distribution facility

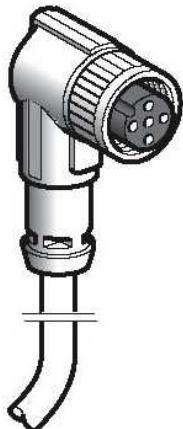

#### Main

Commercial Status	Commercialised
Accessory / separate part category	Cabling accessories
Accessory / separate part type	Pre-wired connectors
Series name	General purpose
Electrical connection	Elbowed female connector M12, 4 pins
Collar material	Metal
Status LED	Without
Cable length	32.81 ft (10 m)

#### Complementary

Cable connector fixing	Screw-on
Cable outer diameter	0.2 in (5.2 mm)
Cable composition	4 x 0.34 mm <sup>2</sup>
Wire insulation material	PUR
[Ue] rated operational voltage	300 V DC 250 V AC
[In] rated current	4 A
Contact resistance	<= 5000 µOhm
Insulating resistance	>= 1 GΩ
Product weight	0.82 lb(US) (0.37 kg)

#### Environment

IP degree of protection	IP67
Ambient air temperature for operation	23...176 °F (-5...80 °C) (flexing) -40...176 °F (-40...80 °C) (static)
Ambient air temperature for storage	-40...176 °F (-40...80 °C)

#### Ordering and shipping details

Category	22483 - MACHINE CABLES
Discount Schedule	DS3
GTIN	00785901763222
Nbr. of units in pkg.	1
Package weight(Lbs)	0.87
Product availability	Non-Stock - Not normally stocked in distribution facility
Returnability	Y
Country of origin	DE

#### Offer Sustainability

Sustainable offer status	Not Green Premium product
RoHS	Compliant - since 0649 -  Schneider Electric declaration of conformity

#### Contractual warranty

Period	18 months
--------	-----------