


KIT 80100-3

Power Supply kit for North America : 12v DC 50 watt switching power supply with barrel power connector P/N 500003900-3 includes power cord P/N 420000100-3 :

1) Power supply P/N 50003900-3 :

Power supply	P/N 500003900-3
Features: Universal Input from 90VAC~264Vac 50/60Hz Desk type & 50W Single Output with Indicator Light Input/Output Specification: Input Voltage: AC 100V~240V 50/60Hz Output Power: 50W Output Voltage: 12V Output Current : 4.16A Efficiency: >80%	
AC input voltage range	90~264VAC, 47~63Hz Max 1.6A
Overload protection	Input: 2A @250Vac
Over Current Protection	Auto recovery
Over voltage protection	Auto recovery
Short Protection	Auto recovery
Withstand voltage	1500Vac 10mA for 3 sec.
Operating temperature	0~40°C
Operating relative humidity	20%-85% RH
Storage Temperature	-40~70°C
Storage relative humidity	10%-95% RH
No Load Standby Power	0.5W max. @ 120Vac
Safety standards	UL,cUL,TUV,CCC,CB,C-TICK
EMC standards	FCC,CE
Dimension (L*W*H)(mm)	110 x 62.2 x 32 mm (±0.2mm)
Life	On-Off life: 10000 times on-off @90Vac Operational life: 50000 hrs@25°C

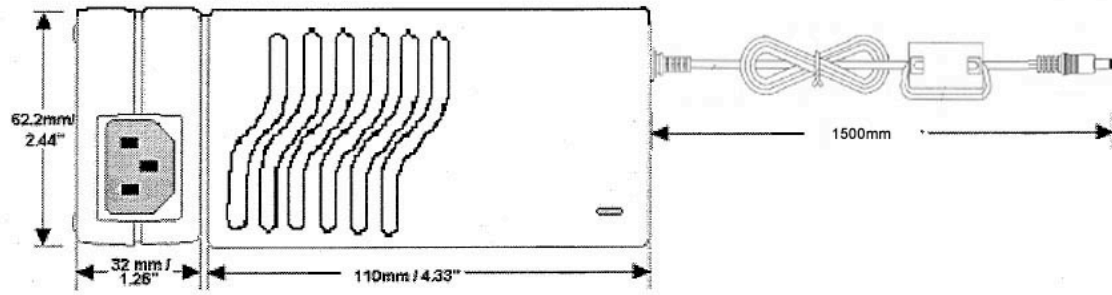


2) Power cord P/N 420000100-3

Power cord	P/N 420000100-3
Cable length	2 meter
Plug standard	Type B – NEMA 5-15
Power plug type	

Power cord drawing :

P/N 420000100-3 :

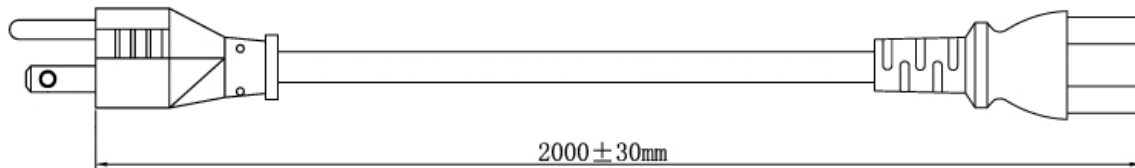

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Digital View:](#)

[KIT 80100-3](#)