



Model 6744

BNC (F/F) Adapter Panel Mount, Hermetically Sealed 75 Ω

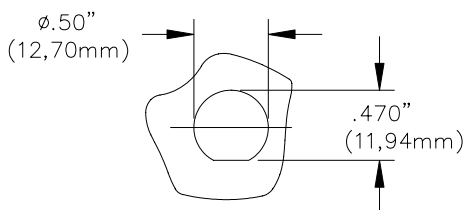

6744 BNC (F/F) Panel Mount Hermetically Sealed-75 Ω

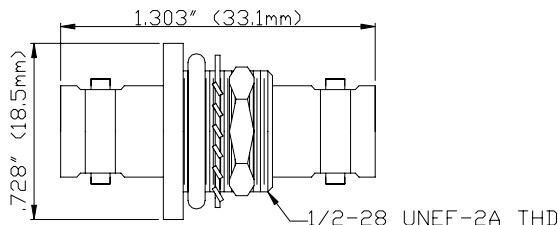

PANEL CUTOUT

Use 75 Ω Pomona BNC connectors with panel or box broadcast applications

Features

- Hermetically sealed.
- Panel mount design.
- Precision machined. Gold plated contacts. Dielectric is PTFE (**not delrin**).

Materials

- Machined brass with tarnish-resistant nickel plating.
- Female center contacts are gold plated heat-treated beryllium copper.
- Precision machined high quality brass (not die cast).
- High quality machined PTFE dielectric.

Ordering Information

Model: 6744 BNC (F/F) Panel Mount
Hermetically Sealed-75 Ω

Specifications

Nominal impedance	75 Ω
Frequency	0-3 GHz
VSWR	1.10 max. 0-1 GHz 1.35 max. 1-3 GHz
Center contact resistance	1.5 m Ω
Insulation resistance	5000 M Ω
Number of insertions	500
Ratings: Voltage: 500 Vrms Operating temperature: -85 °F to +131 °F (-65 °C to +155 °C) Max.	

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 International: 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

6744