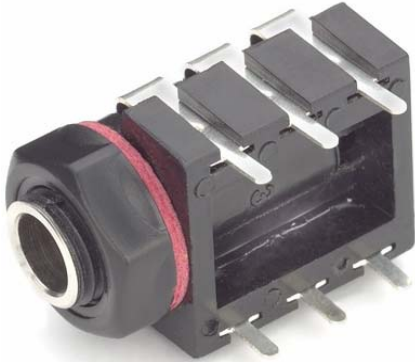


Models 7158 , 7159, 7160
¼" 2 & 3-Cond. Phone Jack, PC Board Mount**Ordering Information**

Model: 7158, 7159, 7160

*Model 7158 Horizontal 3-Conductor Jack, PC Board Mount**Model 7159 Horizontal 2-Conductor Jack, PC Board Mount**Model 7160 Horizontal 3-Conductor Jack, Solder Tabs*

Use to mount securely with PC boards.

Features

- Connects with standard commercial phone plugs
- PC board mountable
- Stereo and mono versions
- Solderable
- 2 and 3 conductor versions

Materials

- Shell: Polyamide 6.6 15% GR
- Contacts: Nickel silver

Specifications

Number of conductors	2 (Mono)-Model 7159 3 (Stereo)-Models 7158, 7160
Contact resistance	< 15 mΩ
Dielectric strength	1000 V dc
Insulations Resistance	1000 MΩ

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[7160](#) [7159](#) [7158](#)