


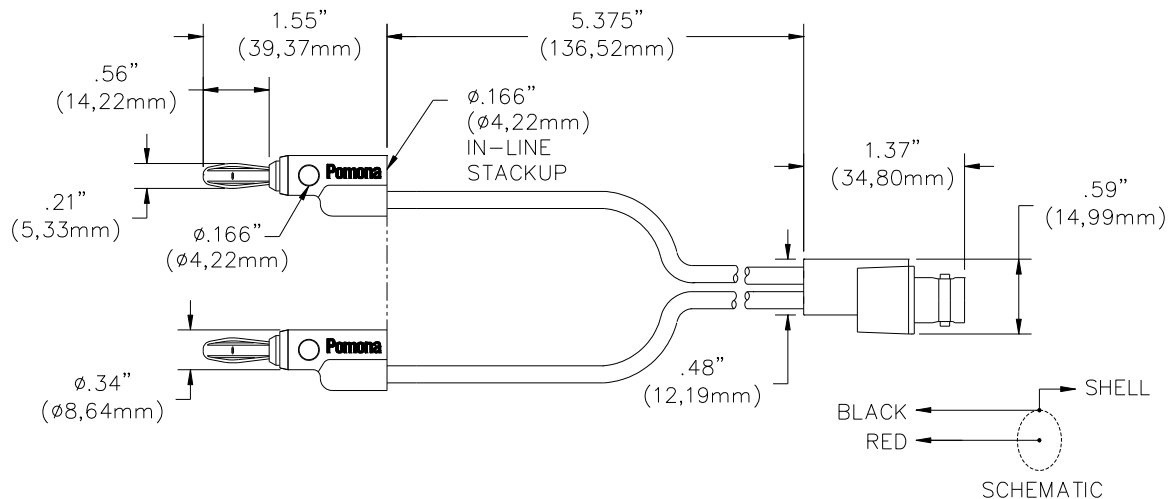

FEATURES:

- Converts BNC cables with male plugs to stackable banana plugs for versatility
- BNC connector and banana plugs are molded directly to the wire for pull strength durability and dust and moisture resistance
- BNC center contact is gold plated Beryllium Copper for corrosion resistance, low contact resistance and long insertion life

MATERIALS:

BNC: Nickel plated brass

Center Contact: Gold plated Beryllium Copper

Wire: 18 AWG, PVC

Marking: "Pomona 3073"

Banana Plugs: Nickel plated brass

Spring: Nickel plated Beryllium Copper

Insulation: Polypropylene, red and black

RATINGS:

Operating Voltage: Hand-held testing: 30VAC/60VDC Max.

Hands free testing in controlled voltage environments: 500 WVDC Max.

Operating Temperature: +55°C (+131°F) Max.

ORDERING INFORMATION:

Model 3073

Custom lengths are available, contact Pomona Technical support: 800-241-2060

(Technicalsupport@pomonatest.com)

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

3073