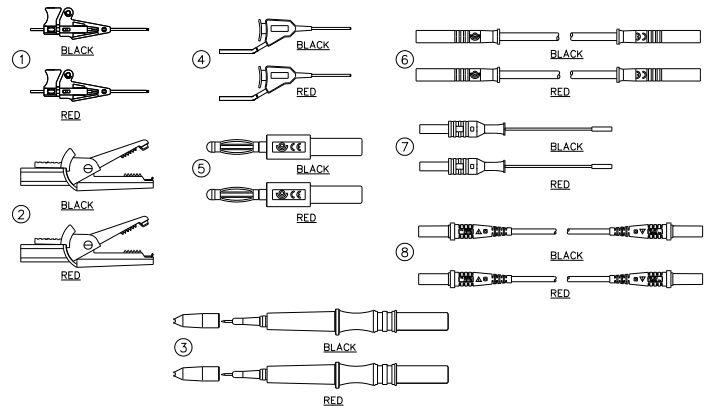


**Model 72928**  
**SMD Multi-Use Test Kit****Kit Includes**

1. 72902-0, -2 Micro SMD Grabber Test Clips (black, red)
  2. 72924-0, -2 Mini-alligator clip with 2mm jack (black, red)
  3. 72923-0, -2 SMD test probe, spring-set tip (black, red)
  4. 72906-0, -2 Mini SMD Grabber Test Clips (black, red)
  5. 72917-0, -2 4mm plug / 2mm plug adapter (black, red)
  6. 5908A Bench-top DMM test leads (black, red)
  7. 72905-0, -2 SMD grabber clip lead (black, red)
  8. 72920-39-0, -2 Stacking 2mm patch cords (black, red)
- Large Folding Test Pouch

**Everything You Need for SMD  
Test with Your DMM in One Kit****Features**

- SMD micro and mini grabbers attach to chip leads with pitches down to 0.008" (0.20 mm).
- Includes all adapters and leads necessary for attachment to standard bench or handheld DMM
- Probe tips are sharp and spring-loaded for solid and steady contact with SMD test points.
- Compatible with all multimeters that accept standard sheathed banana plugs.
- Test accessories conveniently store in four-fold nylon pouch.

**Ordering Information**

Model: 72928

**Specifications**

For specifications for the kit individual components, please see the data sheets for those components at [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

USA: Sales: 800-490-2361 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 International: 425-446-5500

e-mail: [technicalsupport@pomonatest.com](mailto:technicalsupport@pomonatest.com)

Where to Buy: [www.pomonaelectronics.com](http://www.pomonaelectronics.com)

All dimensions are in inches. Tolerances (except noted): .xx =  $\pm 0.02$ " (.51 mm), .xxx =  $\pm 0.005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

72928