
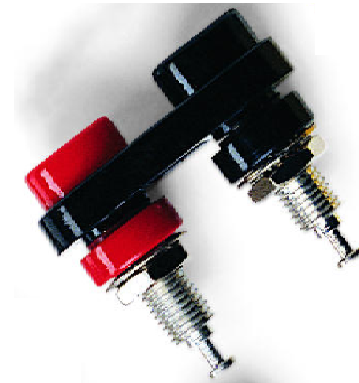
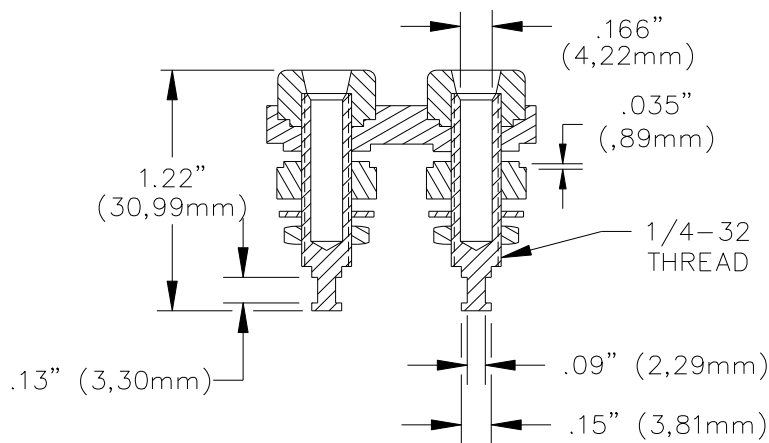
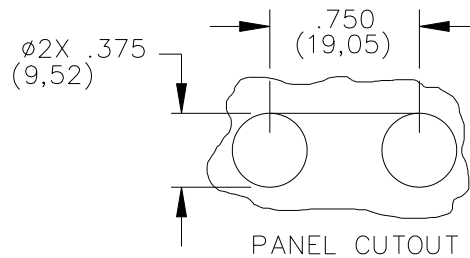


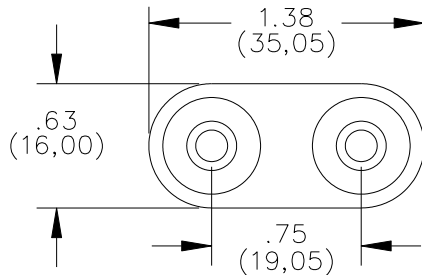

FEATURES:

- ✓ Mounts in panels from .070" to .375" (1.60mm to 9.53mm).

MATERIALS:

Banana Jack: Bright Tin Plated Brass
Mounting Base: Polycarbonate
Insulator: Polycarbonate
Lockwasher: Nickel Plated Steel
Hex Nut: 3/8" 1/4-32 Nickel Plated Brass
Solder Turret: Bright Tin Plated Brass

RATINGS:

Operating Voltage: Hands free usage in controlled voltage environments: 2500 Vrms maximum. *For CE compliance:* not intended for hand-held use at voltages above 33 Vrms/70 Vdc.

Operating Temperature: +239°F (+115°C) Max.

Current: 15 Amperes

ORDERING INFORMATION:

Model 2269-0 (Black Base)
Model 2269-2 (Red Base)

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies.

Sales: 800-490-2361 Fax: 888-403-3360 Technical Support: 800-241-2060 (technicalsupport@pomonatest.com)

For "Where to Buy" information, visit the Pomona web site at www.pomonaelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

[2269-2](#) [2269-0](#)