


**Model CK73041
Calibration Kit****CK73041
CALIBRATION KIT**

The POMONA CK73041 Calibration Kit includes the major connectors and test cables you need for instrument calibration in a comprehensive kit. Versatile adapters and flexible cables greatly expand the variety of test cables you can create, reducing the number of special-purpose patch cords and connectors needed for calibration applications.

For data sheets / specifications of the individual components contained in the CK73041 Calibration Kit, please visit the POMONA website at:
www.pomonaelectronics.com

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

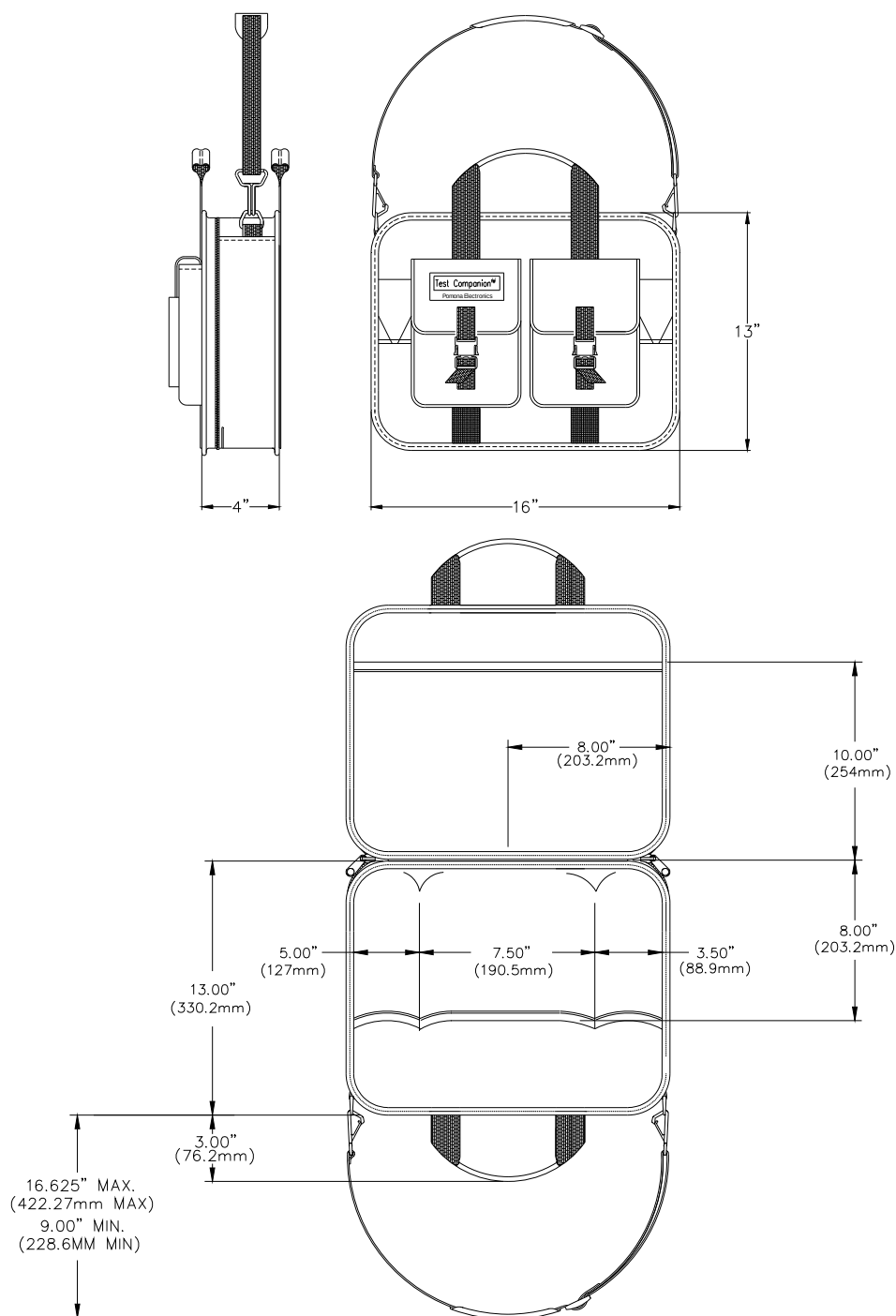
**Model CK73041
Calibration Kit**

MODEL 6146
LARGE TEST COMPANION CARRYING CASE
QTY 1

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm),
.xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions.
Specifications are subject to change without notice. Registered trademarks are
the property of their respective companies.


Model CK73041 Calibration Kit

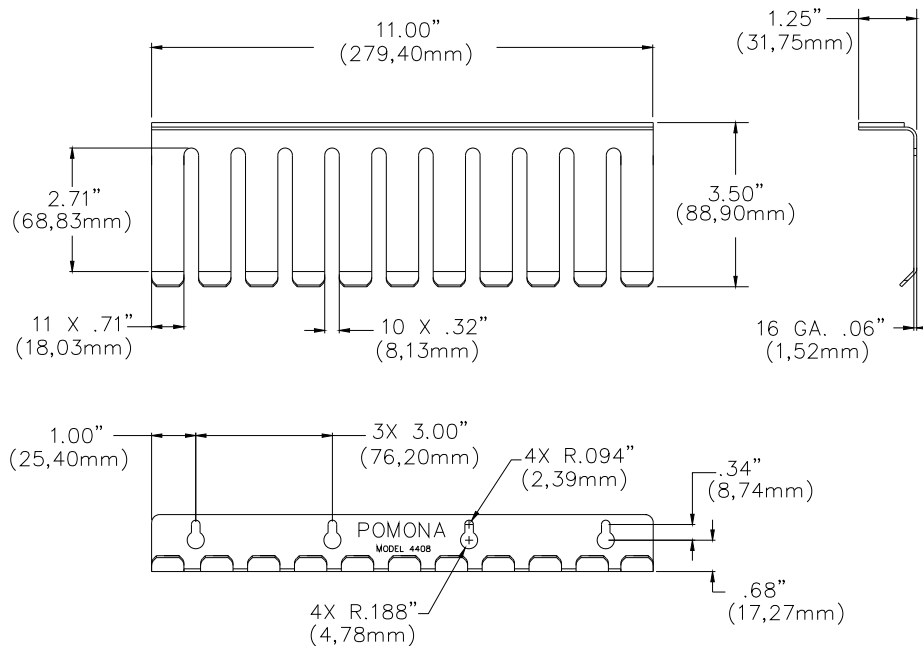


MODEL 4408
TEST LEAD HOLDER
QTY 1



 
MODEL HB-*
PATCH CORD SINGLE STACKING BANANA PLUG
QTY 4: 2 BLACK, 2 RED




MODEL B-*
PATCH CORD SINGLE STACKING BANANA
QTY 8: 4 BLACK, 4 RED

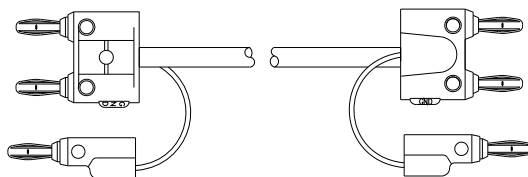


MODEL 1167
PATCH CORD DOUBLE BANANA PLUG
QTY 2

 


MODEL 2249
BNC (M), RG58C/U
QTY 4

 

MODEL 5188
BREAKOUT BNC (F) TO MICROGRABBER
QTY 1:

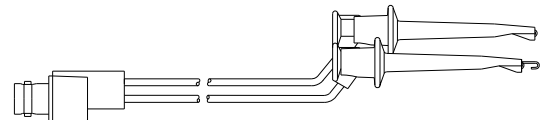


MODEL 3788
BREAKOUT BNC (F) TO MINIGRABBER
QTY 1:

 

MODEL 1756
MICROVOLT SPADE LUG, SHIELDED
QTY 2

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = $\pm .02$ " (.51 mm), .xxx = $\pm .005$ " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

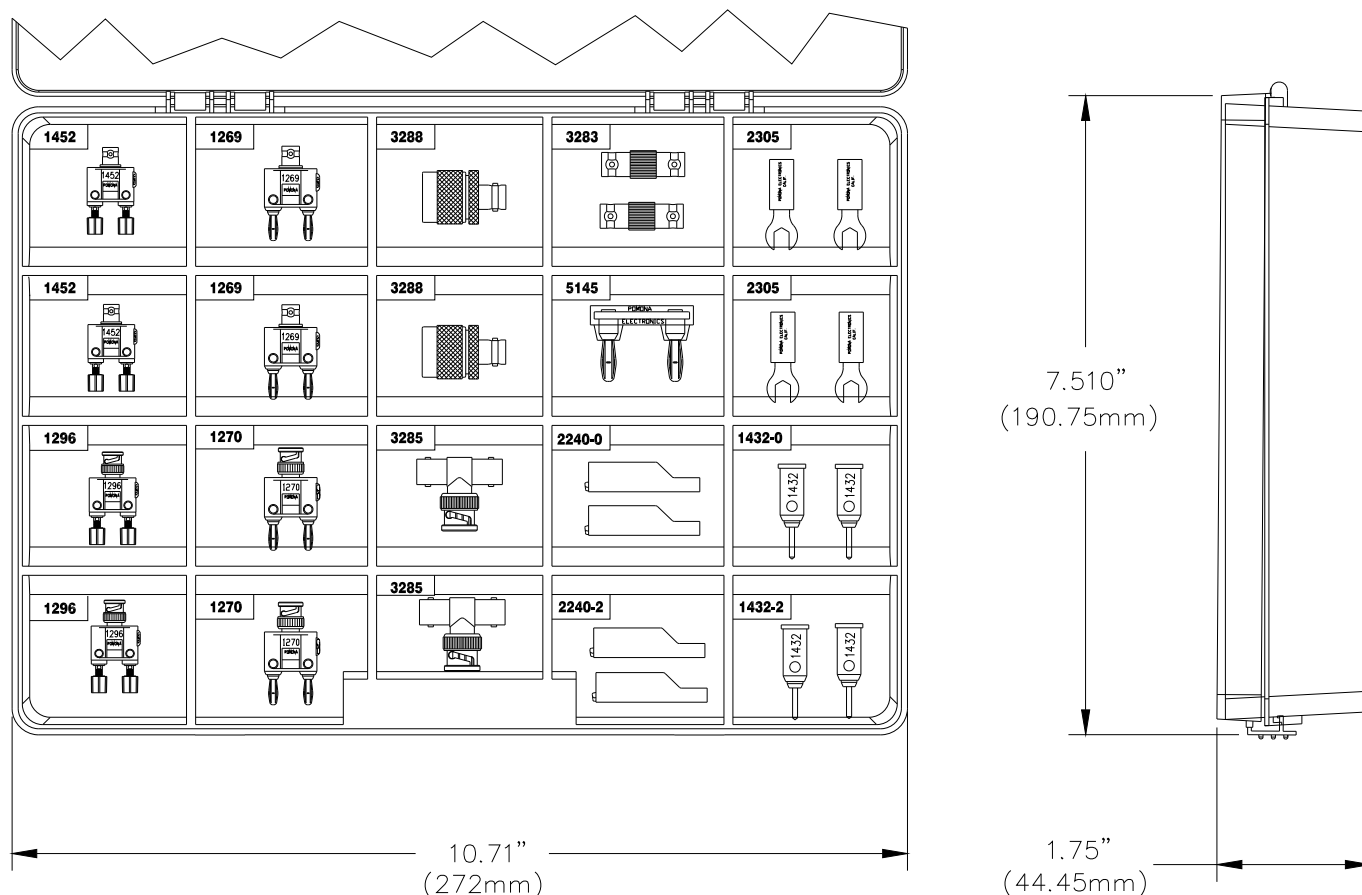**Model CK73041
Calibration Kit****Features**

- **Perfect for:**
 - Field Calibration
 - Outfitting a new technician or lab
 - Comprehensive replacement of important connectors and leads
- **The Calibration Kit allows you to:**
 - Combine connectors with patch cords to create a wide variety of necessary test cables.
 - Reduce the number of test cables needed by creating multiple combinations.
 - Make low voltage precision measurements with shielded low thermal EMF spade lug patch cords.
 - Easily connect to a variety of test equipment with BNC to banana and BNC to binding post adapters.
 - Use shielded coax cables for test and calibration rather than unshielded leads.
 - Turn banana plug patch cords into test leads terminated with alligator clips, spade lugs, or pin tips.
 - Access N Type instrument jacks.
 - Connect to analog components from coaxial cables.
 - Take advantage of shielded dual conductor patch cords.
 - Daisy-chain leads for those long lead situations.

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ± 0.02 " (.51 mm), .xxx = ± 0.005 " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Model CK73041 Calibration Kit

- The **CK73041 CALIBRATION KIT** includes:

Item	Model	Description	Quantity
1	6146	LARGE TEST COMPANION CARRYING CASE	1
2	4408	TEST LEAD HOLDER	1
3	HB-36-0	HORIZONTAL STACKING BANANA PLUG PATCH CORD, 36 INCHES (914.4 mm), BLACK	2
4	HB-36-2	HORIZONTAL STACKING BANANA PLUG PATCH CORD, 36 INCHES (914.4 mm), RED	2
5	B-12-0	STACKING BANANA PLUG PATCH CORD, 12 INCHES (304.8 mm), BLACK	2
6	B-12-2	STACKING BANANA PLUG PATCH CORD, 12 INCHES (304.8 mm), RED	2
7	B-24-0	STACKING BANANA PLUG PATCH CORD, 24 INCHES (609.6 mm), BLACK	2
8	B-24-2	STACKING BANANA PLUG PATCH CORD, 24 INCHES (609.6 mm), RED	2
9	1167-36	DOUBLE BANANA PLUG ON SHIELDED BALANCE LINE, 36 INCHES (914.4 mm)	2
10	1756-48	SHIELDED LOW VOLTAGE SPADE LUG PATCH CORD, 48 INCHES (1219.2 mm)	2
11	2249-C-36	BNC (M) RG58C/U RF CABLE, 36 INCHES (914.4 mm)	4
12	5188	BNC (F) TO MICROGRABBER TEST CLIPS	1
13	3788	BNC (F) TO MINIGRABBER TEST CLIPS	1
14	1269	BNC (F) / DOUBLE BANANA PLUG ADAPTER	2
15	1270	BNC (M) / DOUBLE BANANA PLUG ADAPTER	2
16	1452	BNC (F) / DOUBLE BINDING POST ADAPTER	2
17	1296	BNC (M) / DOUBLE BINDING POST ADAPTER	2
18	2305	SET OF BLACK AND RED MICROVOLT SPADE LUG / BANANA JACK ADAPTER	2 (SETS)
19	2240-0	ALLIGATOR CLIP / BANANA JACK ADAPTER, BLACK	2*
20	2240-2	ALLIGATOR CLIP / BANANA JACK ADAPTER, RED	2*
21	1432-0	PIN TIP / BANANA JACK ADAPTER, BLACK	2*
22	1432-2	PIN TIP / BANANA JACK ADAPTER, RED	2*
23	3283	BNC (F-F) ADAPTER	2
24	3285	BNC (F-M-F) T ADAPTER	2
25	3288	BNC (F) / N TYPE (M) ADAPTER	2
26	5145	DOUBLE BANANA PLUG SHORTING BAR, INSULATED	1

* The model number refers to the standard item which is sold in 10 per package. However, the CK73041 contains only 2 pieces of the item.

Ordering Information

Model: **CK73041**
CALIBRATION KIT

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ± 0.02 " (.51 mm), .xxx = ± 0.005 " (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

CK73041