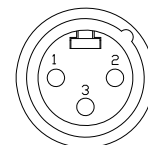
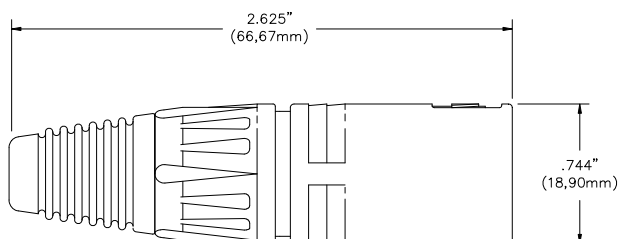
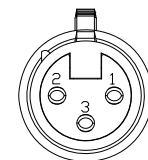
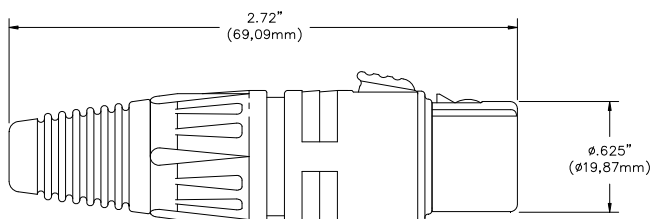


**Model 7283 & 7284
3-Pin In-Line XLR, Silver Contacts, Nickel Finish****Model 7283, 3-Pin (M) In-Line XLR, Silver Contacts, Nickel Finish****Model 7284, 3-Pin (F) In-Line XLR, Silver Contacts, Nickel Finish****Features**

- 3-Pin XLR Plug (7283) and Jack (7284).
- Streamlined profile with compact shell.
- Handles 14 AWG (2.0mm² Max.).
- Low contact Resistance.
- Solderable.

Materials

- *Body*: Die Cast Zinc Alloy with Tarnish Resistant Nickel Finish
- *Contacts*: Silver Plated Brass
- *Strain Relief*: Clamp designed for durability; POM (Polyoxymethylene).

Specifications

Number of Contacts	3
Contact Resistance	≤ 3 mΩ
Dielectric Strength	1500 Vdc
AWG	14 AWG / 2.5mm ² Max.
Pull Strength	45 lbs.
Cable O.D. Range	3.0mm - 6.5mm (0.118" to 0.255")

Ordering Information

Model: 7283, 7284

USA: Sales: 800-490-2361
Technical Support: technicalsupport@pomonatest.com
Fax: 425-446-5844
Europe: 31-(0) 40 2675 150 **International:** 425-446-5500
Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Pomona:

7283