

RESETTABLE CIRCUIT
BREAKER

LIGHTED ON/OFF
POWER SWITCH

482.60 mm
[19.000 in]

43.64 mm
[1.718 in]

165.10 mm
[6.500 in]

38.10 mm TYP
[1.500 in]

ASSEMBLY - VIEW FROM FRONT

19.05 mm
[0.750 in]

444.50 mm
[17.500 in]

5.08 mm
[0.200 in]

67.58 mm
[2.661 in]

6' FOOT
POWER CORD
(NEMA 5-15P)

ASSEMBLY - VIEW FROM BOTTOM

10.31 mm
[0.406 in]

461.98 mm
[18.188 in]


5.97 mm
[0.235 in]

31.70 mm
[1.248 in]


127.00 mm
[5.000 in]

SECTION A-A

R3.18 mm
[0.125 in]

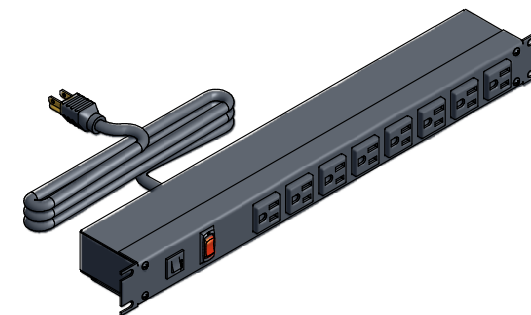

ISOMETRIC VIEW

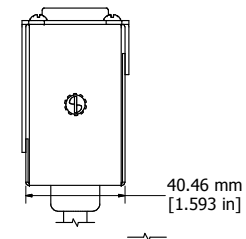

ASSEMBLY - VIEW FROM SIDE

1582H8A1BK

Finish - Front - Black Painted Steel

Back - Black Painted Steel

Rated - 125 VAC, 60 Hz, 15 Amps

Approvals - CSA Certified Standards C22.2 (No. 21-95, 42-99)

- UL Recognized Standard UL1363

Colours & Cord Length

1582H8A1BK - Black w/ 6' Foot Power Cord (NEMA 5-15P)

1582H8A1- ASA 61 Grey w/ 6' Foot Power Cord (NEMA 5-15P)

1582H8B1BK - Black w/ 15' Foot Power Cord (NEMA 5-15P)

1582H8B1- ASA 61 Grey w/ 15' Foot Power Cord (NEMA 5-15P)

**HAMMOND
MANUFACTURING™**
1582H8A1BK
www.hammondmfg.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[1582H8A1](#) [1582H8B1](#) [1582H8A1BK](#) [1582H8B1BK](#)