

Energy Limiting (BP Series)




CLASS 2 - PLUG IN ENERGY LIMITING TRANSFORMERS

- Used in AC powered chimes, door bells, security systems, decorative lighting, furnaces, humidifiers, appliances, vending machines and intercom system type applications.
- Enclosed in an attractive plug in black plastic case.
- For indoor use only
- Input 120VAC - 20VA units are inherently limited - no fuses or circuit breakers.
- 40VA units use an internal slow blow fuse.
- Secondary - 2 recessed slot head screw terminals (on plug side).
- All models are 60 Hz.
- CSA certified (#LR 113601) and UL listed (#E 184936)

Part No.	A.C. Input (Primary) V (RMS)	A.C. Output Secondary (RMS)		Power Rating VA
		V	A	
BPD2E	120	12	1.67	20
BPD2EE	120	14	1.43	20
BPD2F	120	16	1.25	20
BPD2FF	120	18	1.11	20
BPD2G	120	24	0.83	20
BPE2E	120	12	3.33	40
BPE2EE	120	14	2.86	40
BPE2F	120	16	2.50	40
BPE2FF	120	18	2.22	40
BPE2G	120	24	1.67	40

Class 2

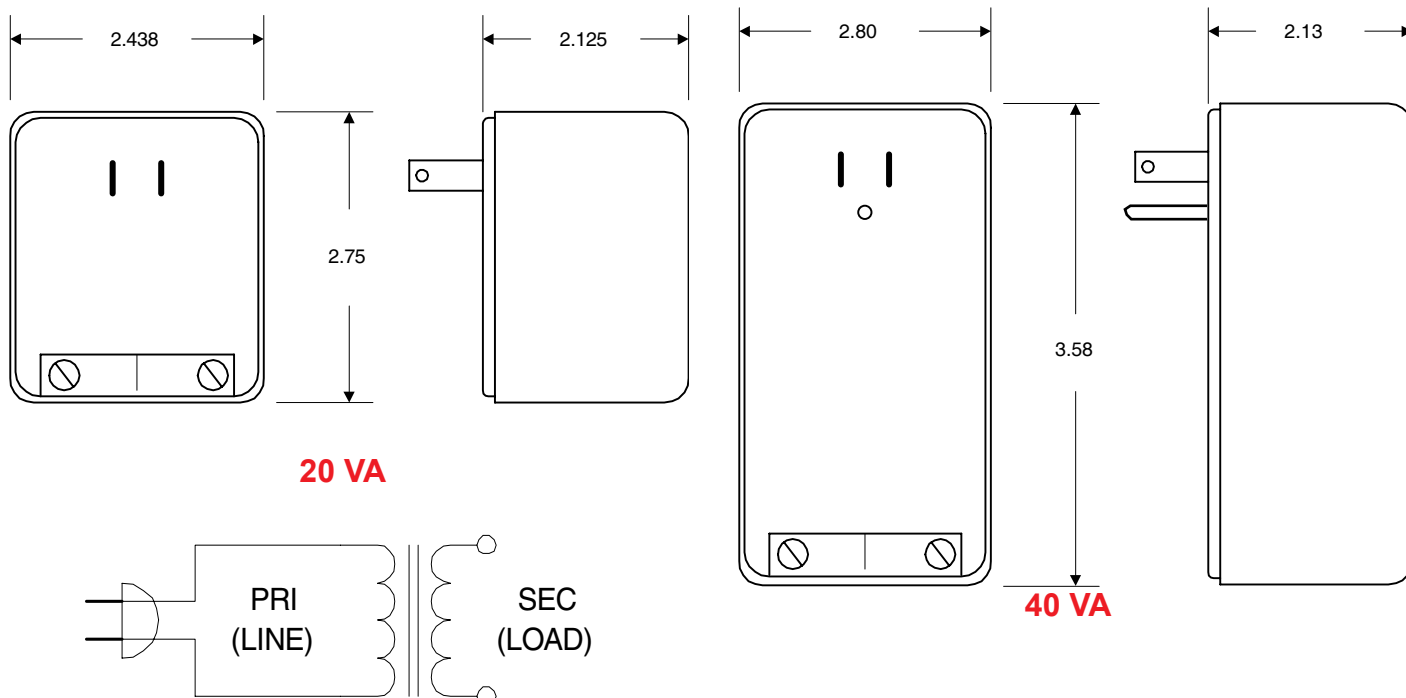

CANADA
Guelph, Ontario (519) 822-2960
St. Laurent, Quebec (514) 343-9010
USA
Cheektowaga, NY (716) 630-7030

www.hammondmfg.com



EUROPE
Basingstoke, UK 01256 812812

AUSTRALIA
Queenstown, Australia 61-8-8240-2244

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Hammond:](#)

[BPD2FF](#) [BPE2EE](#) [BPD2F](#) [BPD2G](#) [BPD2E](#) [BPE2F](#) [BPE2G](#) [BPE2E](#) [BPE2FF](#) [BPD2EE](#)