

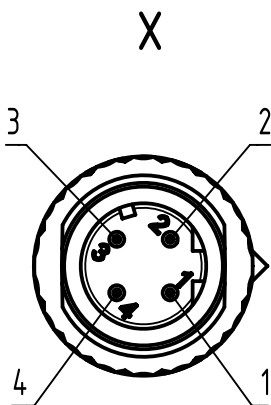


M12 D-coded 4 poles, straight overmolded male connector

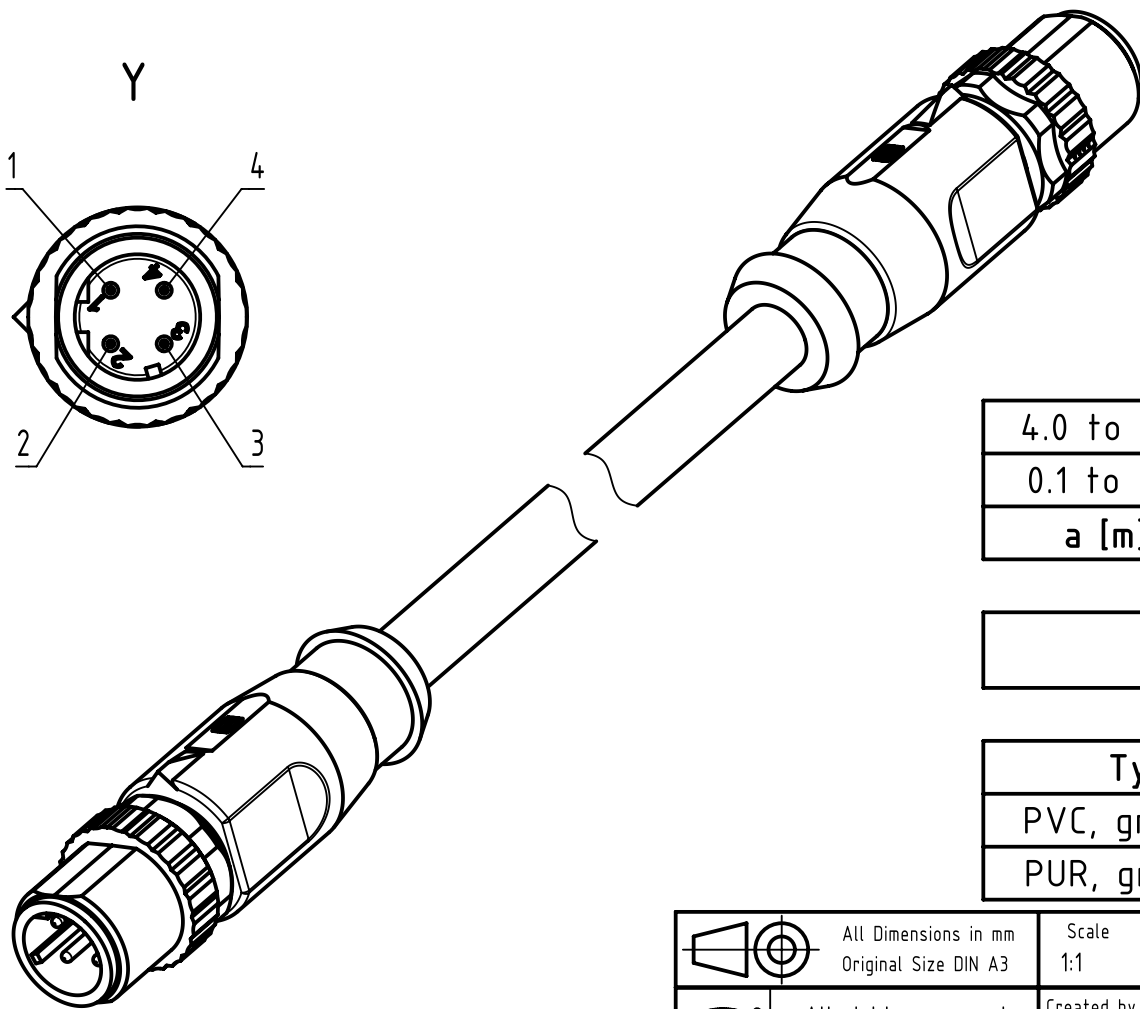

Loading-Plan:

1	shield	1
2	yellow	2
3	white	3
4	orange	4
	blue	

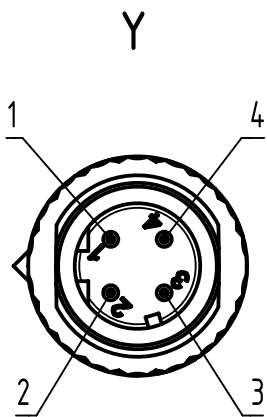

4.0 to 100	+1%
0.1 to 3.9	+0.04
a [m]	Tolerance

length in "1m" step	100	XXX=000
	99	XXX=990
	.	.
	12	XXX=120
length in "0.1m" step	11	XXX=110
	10	XXX=100
	9.9	XXX=099
	9.8	XXX=098
	.	.
	0.4	XXX=004
	0.3	XXX=003
	0.2	XXX=002
Step	0.1	XXX=001
	a [m]	XXX

Part no.	213492924XXXXX
----------	----------------

Type of cable	XX
PVC, green, 4xAWG22/7	XX=05
PUR, green, 2x2xAWG22	XX=77

- Protection level: IP67
- Temperature range: -30°C ... +70°C

	All Dimensions in mm Original Size DIN A3		Scale 1:1	Free size tol.		Ref.
	All rights reserved		Created by TOMUTA	Inspected by AVRAM	Standardisation HOFFMANN	Sub.
HARTING Electronics GmbH D-32339 Espelkamp	Department EC PD - RO		Title M12 D-coded Cable Assembly			Doc-Key / ECM-Nr. 100588528/UGD/000/A 50000079044
			Type TB	Number 213492924XXXXX		Rev. A
						Page 1/1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HARTING:

[21349292477010](#) [21349292477050](#) [21349292477075](#) [21349292477100](#)