

38999


PART # Commercial

Part number reference. To complete, see how to order pages 62-66.

Connector Type	Shell Style	Service Class	Shell Size & Insert Arrg	Contact Type	Alternate Position	Special Variations
JTG/JTNG	06	RE	22-2	P	A	(XXX)

Military

MS Number	Service Class	Shell Size	Finish	Insert Arrg	Contact Style (P or S)	Alternate Position
MS27484	E	14	A	18	P	A

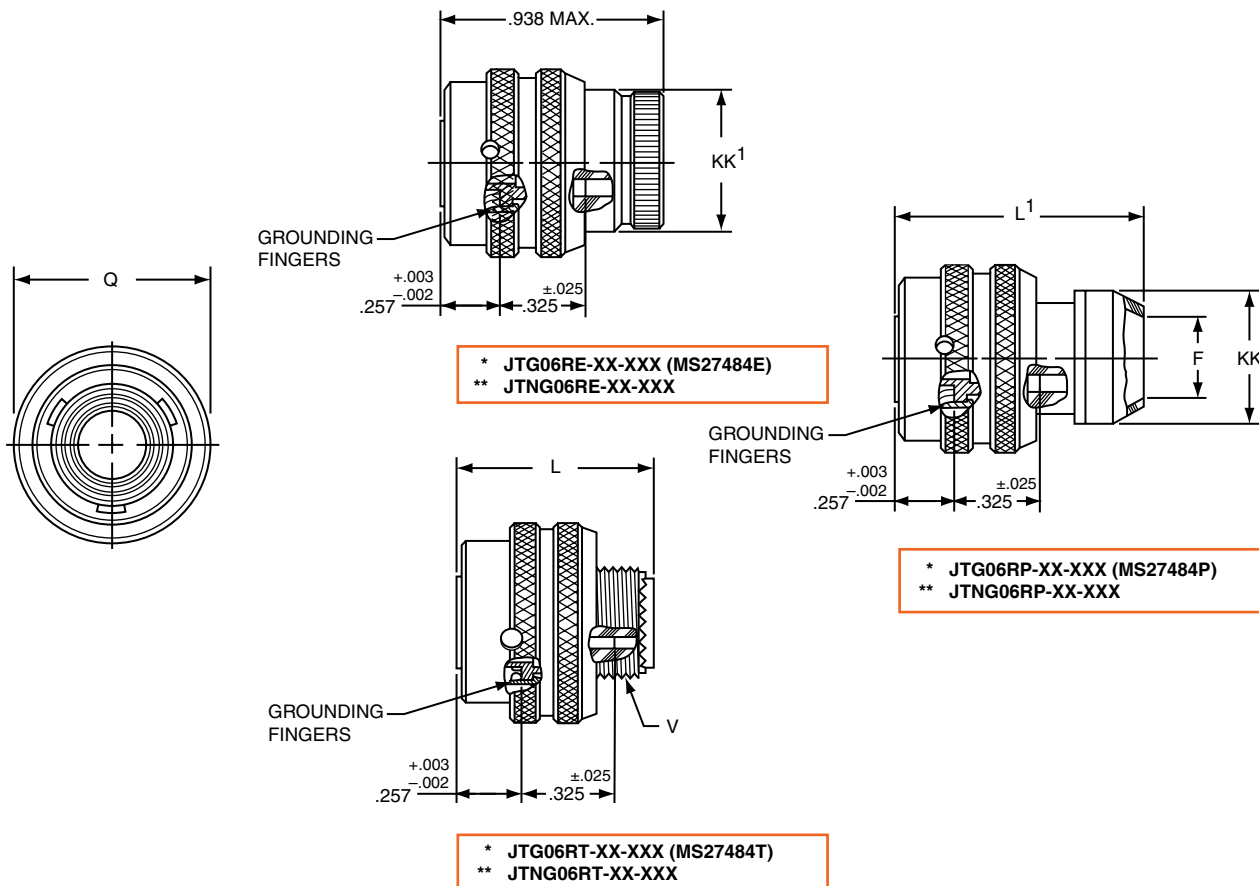

* Plug with grounding fingers
** Clear iridite finish (gold color), N₂O₄ resistant

Shell Size	F Dia.	L Max.	L ¹ Max.	Q Dia Max.	V Thread Modified		KK Dia. Max.	KK ¹ Dia. Max.
					Class 2A UNEF	Modified Major Dia.		
8	.444	.891	1.000	.734	.4375-28	.421 – .417	.625	.578
10	.558	.891	1.000	.844	.5625-24	.542 – .538	.750	.703
12	.683	.891	1.000	1.016	.6875-24	.667 – .663	.875	.828
14	.808	.891	1.000	1.141	.8125-20	.791 – .787	1.000	.953
16	.909	.891	1.000	1.265	.9375-20	.916 – .912	1.125	1.078
18	1.034	.891	1.000	1.391	1.0625-18	1.034 – 1.030	1.250	1.203
20	1.159	.891	1.000	1.500	1.1875-18	1.158 – 1.154	1.375	1.328
22	1.284	.891	1.000	1.625	1.3125-18	1.283 – 1.279	1.500	1.453
24	1.409	.891	1.062	1.750	1.4375-18	1.408 – 1.404	1.625	1.578

All dimensions for reference only.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Amphenol:](#)

[MS27484E14F35BD](#) [MS27484E16F6BA](#) [MS27484E16F6A](#) [MS27484E16F6AB](#) [MS27484E16F6BB](#)
[MS27484E16F6BC](#) [MS27484E16F6BD](#) [MS27484E16F8AA](#) [MS27484E16F8BC](#) [MS27484E16F8AD](#)
[MS27484E16F26BB](#) [MS27484E16F35AA](#) [MS27484E16F35BA](#) [MS27484E16F35AB](#) [MS27484E16F35B](#)
[MS27484E16F35BB](#) [MS27484E16F99BA](#) [MS27484E16F99A](#) [MS27484E16F99BC](#) [MS27484E18F11A](#)
[MS27484E18F11AB](#) [MS27484E18F28AC](#) [MS27484E18F28AD](#) [MS27484E18F30BC](#) [MS27484E18F32A](#)
[MS27484E18F32AB](#) [MS27484E18F32AD](#) [MS27484E18F32BD](#) [MS27484E18F35AA](#) [MS27484E18F35A](#)
[MS27484E18F35B](#) [MS27484E18F35AC](#) [MS27484E18F35BC](#) [MS27484E18F35BD](#) [MS27484E20F16AA](#)
[MS27484E20F16AB](#) [MS27484E20F16BB](#) [MS27484E20F16AC](#) [MS27484E20F16AD](#) [MS27484E20F35AB](#)
[MS27484E20F35B](#) [MS27484E20F39BB](#) [MS27484E20F39BC](#) [MS27484E20F39AD](#) [MS27484E20F41AA](#)
[MS27484E20F41A](#) [MS27484E20F41AB](#) [MS27484E20F41AC](#) [MS27484E20F41BD](#) [MS27484E22F2AA](#)
[MS27484E22F2BA](#) [MS27484E22F2A](#) [MS27484E22F2AB](#) [MS27484E22F2AC](#) [MS27484E22F2BD](#)
[MS27484E22F21BA](#) [MS27484E22F21AB](#) [MS27484E22F21BB](#) [MS27484E22F21AC](#) [MS27484E22F21BC](#)
[MS27484E22F32AC](#) [MS27484E22F32AD](#) [MS27484E22F35BB](#) [MS27484E22F35AC](#) [MS27484E22F35BC](#)
[MS27484E22F55AA](#) [MS27484E22F55AB](#) [MS27484E22F55BB](#) [MS27484E22F55AC](#) [MS27484E22F55AD](#)
[MS27484E24F4AA](#) [MS27484E24F4BA](#) [MS27484E24F4B](#) [MS27484E24F4BD](#) [MS27484E24F24BA](#)
[MS27484E24F24A](#) [MS27484E24F24AC](#) [MS27484E24F29AA](#) [MS27484E24F29AB](#) [MS27484E24F29AD](#)
[MS27484E24F29BD](#) [MS27484E24F35BA](#) [MS27484E24F35A](#) [MS27484E24F35AC](#) [MS27484E24F61AB](#)
[MS27484E24F61BB](#) [MS27484E24F61BD](#) [MS27484E10F98SA](#) [MS27484E12A4S](#) [MS27484E12B3PB](#)
[MS27484E12F35SB](#) [MS27484E12F98PB](#) [MS27484E12F98PC](#) [MS27484E14B18A](#) [MS27484E24A4P](#)
[MS27484T10F99PD](#) [MS27484T12A98PA](#) [MS27484T14B97S](#) [MS27484T18B96PA](#) [MS27484T18F32SB](#)