

AMS-39 SERIES

STANDARD SURFACE MOUNT CONTACT





- UL and ULC Listed
- 3/4" operating gap
- Spacers and covers included
- Available in white, brown, gray, or ivory*

Application

The AMS-39 Series Standard Surface Mount Contact is a UL listed contact designed to protect a wide variety of openings such as: man doors, sliding doors, windows, cabinets, hatches, and many others.

Dimensions

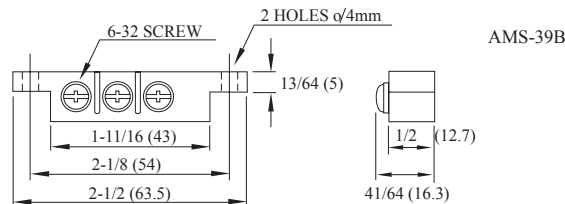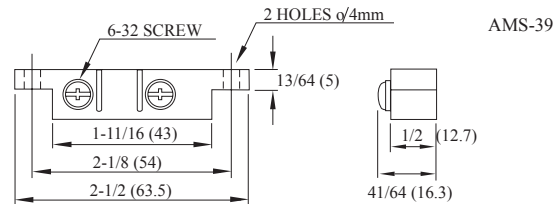

Specifications

Model	Color	Stock Number	Contact	Contact Rating	Contact Type	Max. Carry Current	Max. Switching Current	Breakdown Voltage	Operating Gap	Mounting Method	Operating Temperature Range
AMS-39	White	4350190	Terminal	10VA	Form A N.O	1.0 Amp	.4 Amp	200VDC	3/4"	Screw	32°F to 120°F (0°C to 49°C)
	Brown	4350187									
	Gray	4350188									
	Ivory	4350189									
AMS-39B	White	4350204		3VA	Form C N.O./N.C.	.5 Amp	.2 Amp	150VDC			
	Brown	4350202									
	Ivory	4350078									
AMS-39CVS (includes screws, covers, and spacers) 5 sets per pack	White	4350186		10VA	Form A N.O.	1.0 Amp	.4 Amp	200VDC			
	Brown	4350184									
	Gray	4350067									
	Ivory	4350185									

* AMS-39B not available in gray

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

AMSECO:

[505-391B](#) [505-391G](#) [505-395W](#) [505-392B](#) [505-392W](#) [505-395B](#) [505-391W](#) [AMS-39MG-B](#) [AMS-39B-W](#) [AMS-39B-B](#) [AMS-39MGW](#) [AMS-39-G](#) [AMS-39-W](#) [AMS-39CVS-W](#)