


AMS-17 SERIES

3/8" MINI RECESSED CONTACT

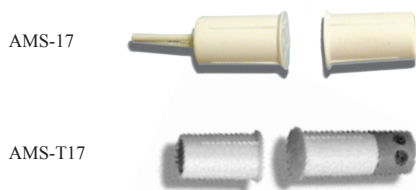


- UL Listed
- 5/16" operating gap
- Alnico 5 magnet
- Optional AD-17 adapter available
- Available in white, brown, or ivory

Application

The AMS-17 Series Mini Recessed Contact is a UL listed contact designed to provide a clean and easy installation for standard openings. The AMS-17 Series is ideal for areas where small size is important. These contacts may be used to secure a variety of openings such as: man doors, sliding doors, windows, and other openings where a small concealed contact is necessary.

Dimensions

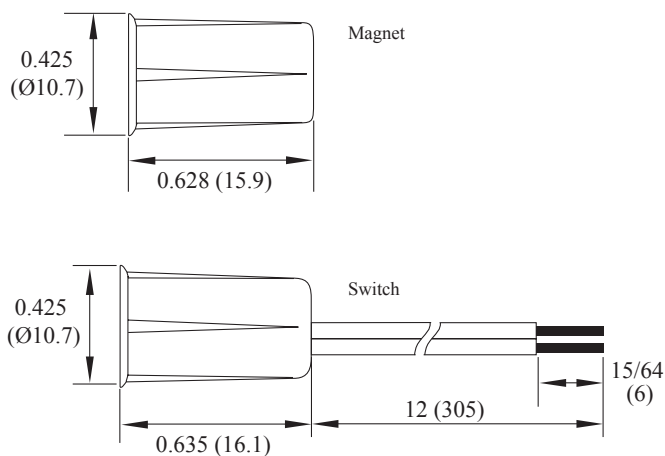

Specifications

Model	Color	Stock Number	Contact	Contact Rating	Contact Type	Max. Carry Current	Max. Switching Current	Breakdown Voltage	Operating Gap	Mounting Method	Operating Temperature Range
AMS-17	White	4350121	22AWG 12" Lead	1.0VA	Form A N.O	.3 Amp	.1 Amp	150VDC	5/16"	Press fit	32°F to 120°F (0°C to 49°C)
	Brown	4350118									
	Ivory	4350120									
AMS-T17	White	4350225	Terminal								
	Brown	4350094									
	Ivory	4350224									
AD-17	White	4350128	Allows 3/8" switch to be placed in a 3/4" hole.								
	Brown	4350127									

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[AMSECO:](#)

[505-171W WHITE](#) [505-171B BROWN](#) [AMS-17-B](#) [AMS-17-W](#)