



.100 CENTERS C Series Probes


SURFACE MOUNT

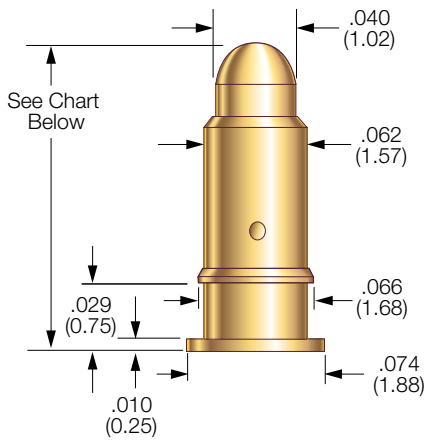

THRU HOLE MOUNT

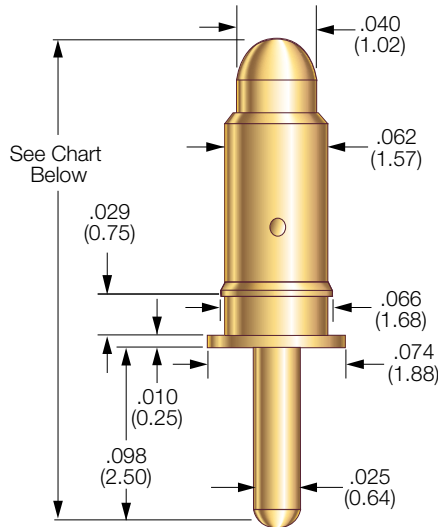

SOLDER CUP

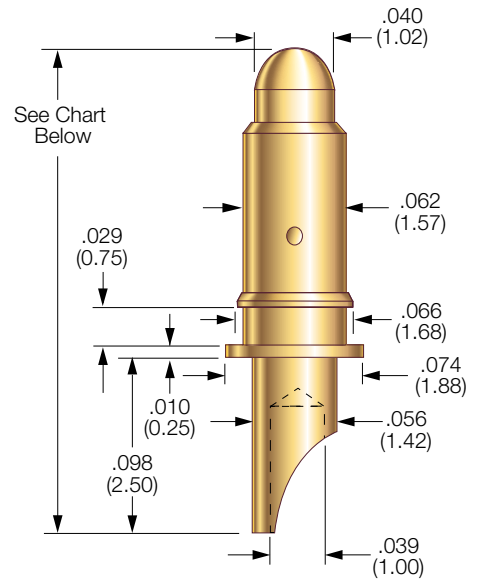

PROBE SPECIFICATIONS

Minimum Centers: .100 (2.54)

Current Rating:

CG Series: 10 amps continuous

CP Series: 10 amps continuous

CS Series: .5 amp continuous

(Individual probe in free air @ ambient temperature)

Typical Resistances:

CG Series: < 10 mΩ

CP Series: < 10 mΩ

CS Series: < 60 mΩ

Spring Force:

3.1 oz. (88g) @ working travel for 4mm compressed length series

2.9 oz. (82g) @ working travel for 6mm compressed length series

MATERIALS

Barrel: Brass, gold plated

Spring: Stainless steel

Plunger:

CG Series: Brass, gold plated

CP Series: Brass, gold plated

CS Series: Brass, Duralloy™ plated

Special Features:

CG Series: Bias plunger design

CP Series: Bias plunger design

CS Series: Standard design

Recommendations:

Mounting hole: .064/.065 (1.62/1.65)

Pad size for Surface Mount: .085 (2.20)

Wire gage for Solder Cup: 20 gage max.

Drill size for Thru Hole Tail: .035 (0.89)

Overall Length

Series	SURFACE Mount	Thru Hole	Solder Cup
CG-2.5-4	.197 (5.00)	.295 (7.50)	.295 (7.50)
CG-2.5-6	.335 (8.50)	.433 (11.00)	.433 (11.00)
CP-2.5-4	.185 (4.70)	.283 (7.20)	.283 (7.20)
CP-2.5-6	.315 (8.00)	.413 (10.50)	.413 (10.50)
CS-2.5-4	.185 (4.70)	.283 (7.20)	.283 (7.20)
CS-2.5-6	.315 (8.00)	.413 (10.50)	.413 (10.50)

Travel

Series	Working Travel	Maximum Travel
CG-2.5-4	.039 (1.00)	.039 (1.00)
CG-2.5-6	.098 (2.50)	.098 (2.50)
CP-2.5-4	.028 (0.71)	.028 (0.71)
CP-2.5-6	.079 (2.00)	.079 (2.00)
CS-2.5-4	.028 (0.71)	.028 (0.71)
CS-2.5-6	.079 (2.00)	.079 (2.00)

HOW TO ORDER

CS

SERIES

2.5

PITCH (MM)

4

COMPRESSED
LENGTH (MM)

SM

TERMINATION

SERIES:
CG: Ground Connector Probe
CP: Power Connector Probe
CS: Signal Connector Probe

4: 4 mm
6: 6 mm

SM: Surface Mount
TH: Thru Hole
SC: Solder Cup

View updates of this information at www.idinet.com

Specifications subject to change without notice. Dimensions in inches (millimeters)



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Smiths Interconnect:](#)

[CG-2.5-4-SM](#) [CG-2.5-6-SC](#) [CP-2.5-4-SC](#) [CP-2.5-4-SM](#) [CP-2.5-6-SC](#) [CS-2.5-4-SC](#) [CS-2.5-4-SM](#) [CS-2.5-4-TH](#)
[CS-2.5-6-SC](#) [CS-2.5-6-SM](#) [CS-2.5-6-TH](#)