
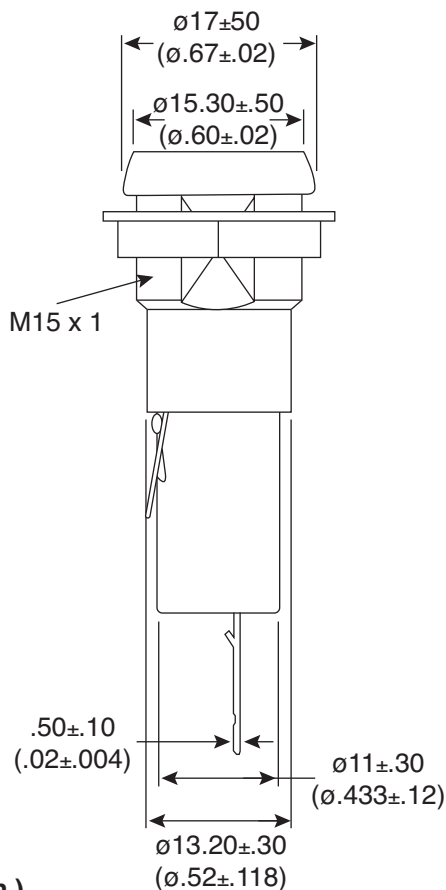
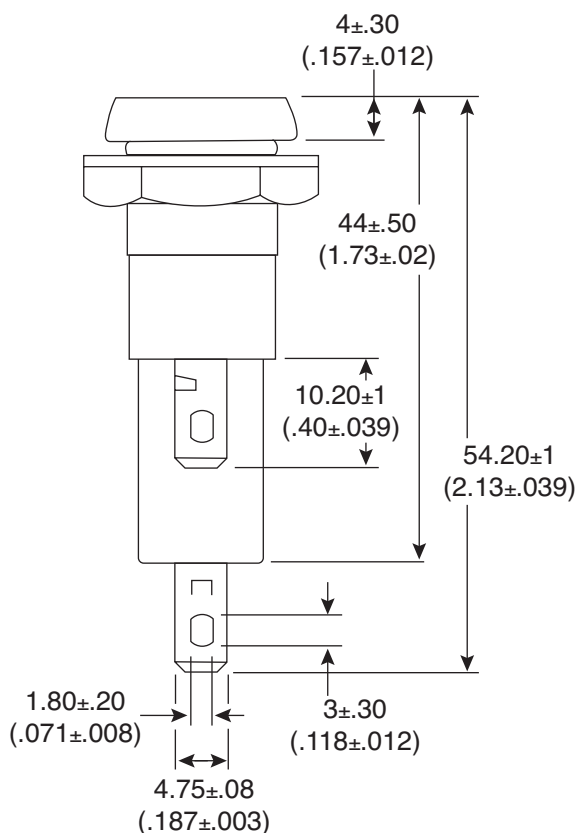


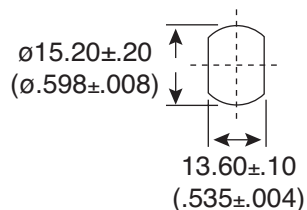

Dimensions: mm (in.)

SPECIFICATIONS

Rating:	15A/250V AC
Insulation Resistance:	500VDC 100M OHM Min.
Dielectric Strength:	1500VAC for 1 minute
Body:	Phenolic
Cap:	PBT
RoHS Compliant	

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

EPD-200529

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eagle Plastic Devices:](#)

[441-R344B-GR](#)