
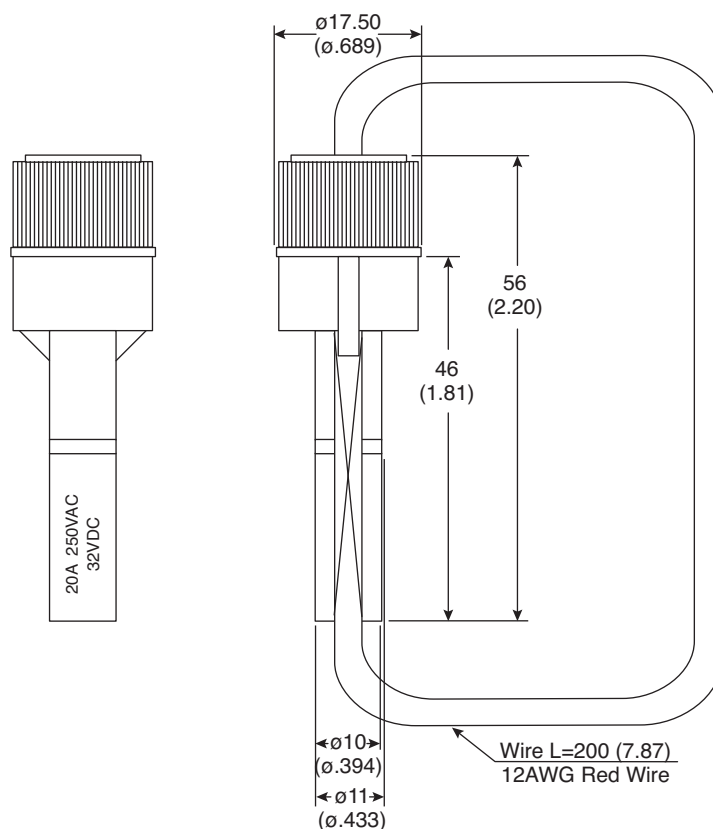


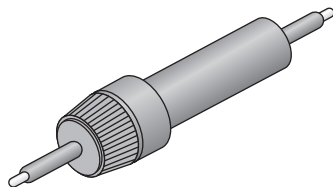

DIMENSIONS: mm (in.)

SPECIFICATIONS	
Rating:	20A/250VAC, 32VDC
Insulation Resistance:	500VDC 100M Ω Min.
Dielectric Strength:	1000VAC 1 minute
Fuse Size:	$\phi 5.2 \times 20$ mm
Tolerance:	+/- 0.5mm unless otherwise specified
RoHS Compliant	

Available from Mouser Electronics
1-800-346-6873
www.mouser.com

EPD-200560

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Eagle Plastic Devices:](#)

[441-R332A-GR](#)