


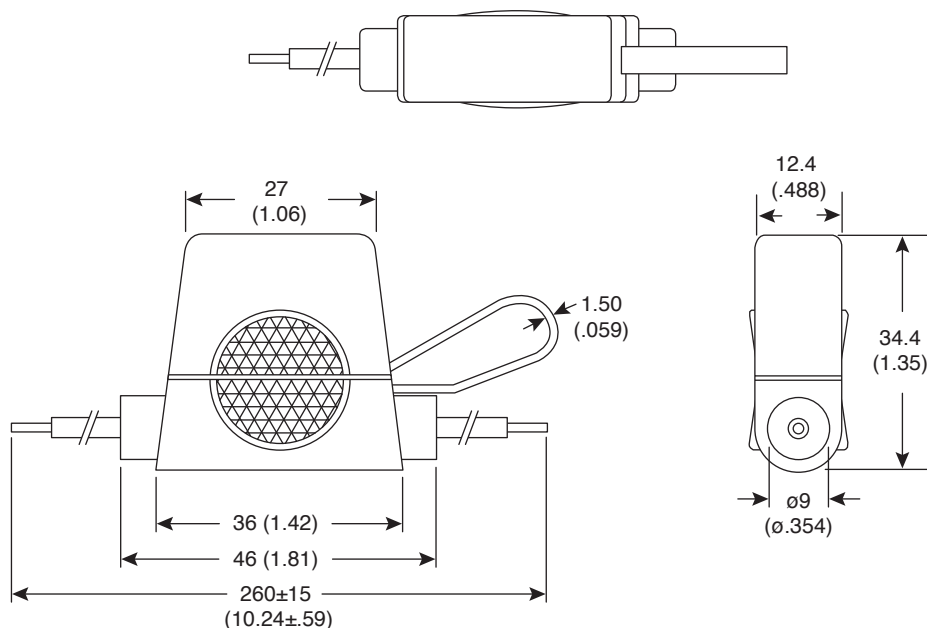

Dimensions: mm (in.)

Type	Wire	Rating	Wire Color
441-R347A-GR	12AWG	30A 32 VDC	Red
441-R347B-GR	14AWG	20A 32 VDC	Red
441-R347C-GR	16AWG	15A 32 VDC	Red
441-R347D-GR	18AWG	10A 32 VDC	Red

SPECIFICATIONS	
Rating:	12-24 VDC
Contact Resistance:	50m Ω max.
Insulation Resistance:	500VDC 100M Ω min.
Dielectric Strength:	1500 VAC, 1 minute
Fuse Type	ATO Blade Fuse
RoHS Compliant	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Eagle Plastic Devices:

[441-R347D-GR](#) [441-R347A-GR](#) [441-R347B-GR](#) [441-R347C-GR](#)