


AC Power Inlet

161-0717-187-E

KOBI CONN

AC Power Inlet

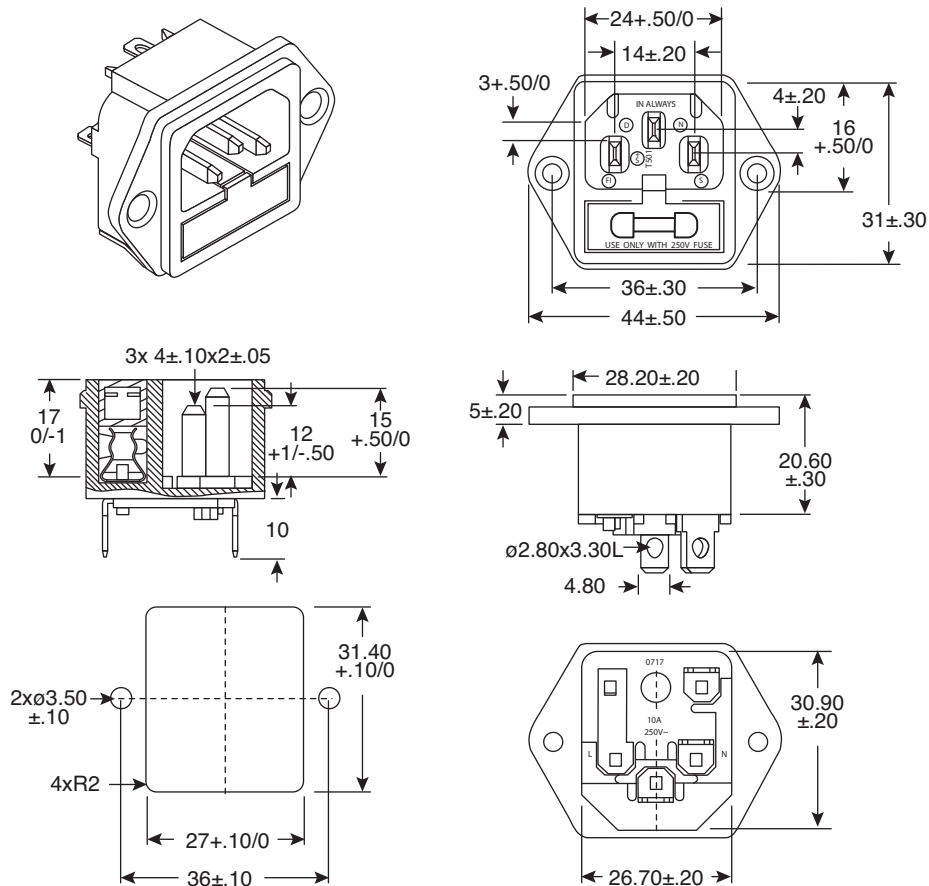

DIMENSIONS: mm

SPECIFICATIONS

Type:	Screw in mount w/miniature fuse holder
Housing:	Thermoplastic
Terminal:	Tin plated copper alloy, .187" faston/solder tab
Rating:	250VAC 10A / 250VAC
Insulation Resistance:	Over 100M Ω @ 500VDC
Dielectric Strength:	2000VAC 6.3A max.
Fuse:	ϕ 5x20mm 250VAC 6.3A max.
RoHS Compliant	

Date Last Revised: 6-5-09

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301138

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

161-0717-187-E

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-0717-187-E](#)