


IEC 60320 C14 Inlet

161-R3019013-E

KOBI CONN

IEC 60320 C14 Inlet

161-R3019013-E

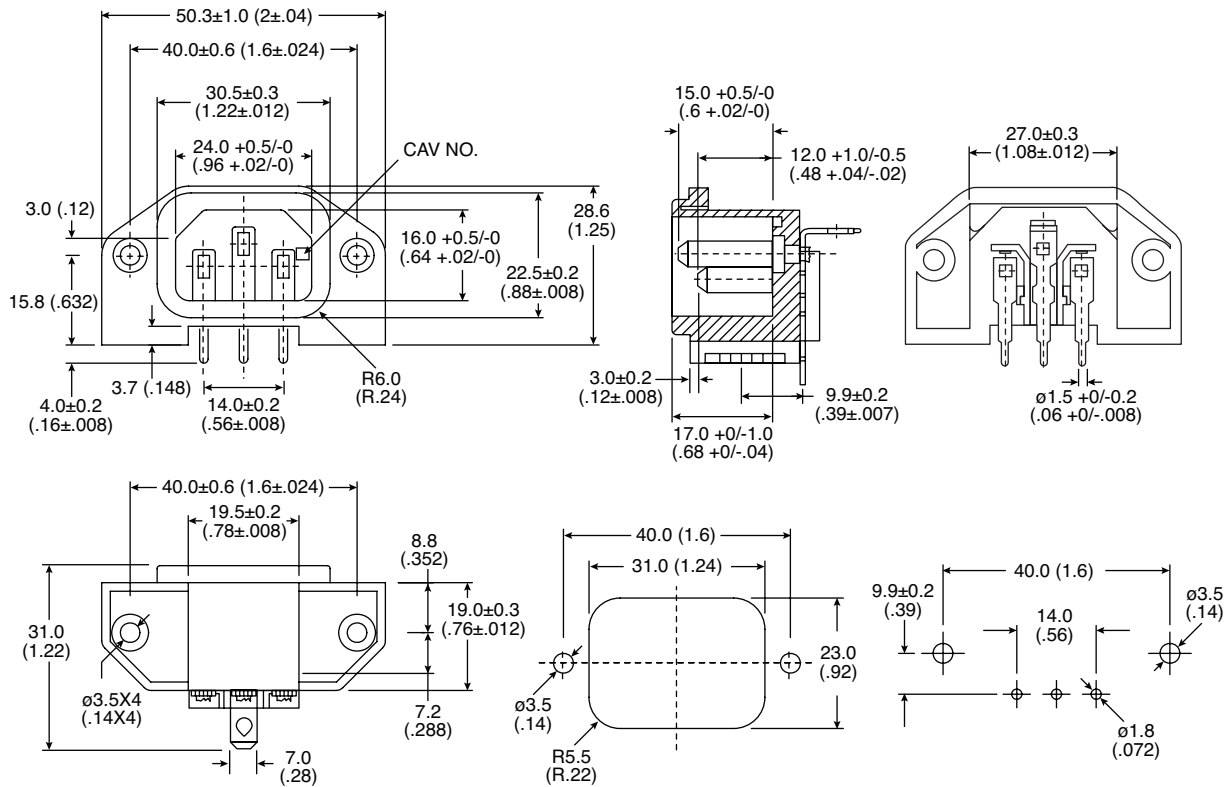

Dimensions: mm (in.)

MATERIALS

Body:	Black Glass-Fiber Thermoplastic
Contact Pin:	Brass Strip 2.0 ± 0.05
Insulator:	Black Color

SPECIFICATIONS

Rating:	10A, 250VAC
Insulation Resistance:	Over 100MΩ at 500VDC
Dielectric Strength:	2000VAC for 1 Minute

RoHS Compliant

Date Last Revised: 07-27-07

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC- 301172

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[161-R3019013-E](#)