


3.5mm Stereo Plug

171-PA3291-1-E

KOBICONN

3.5mm Stereo Plug

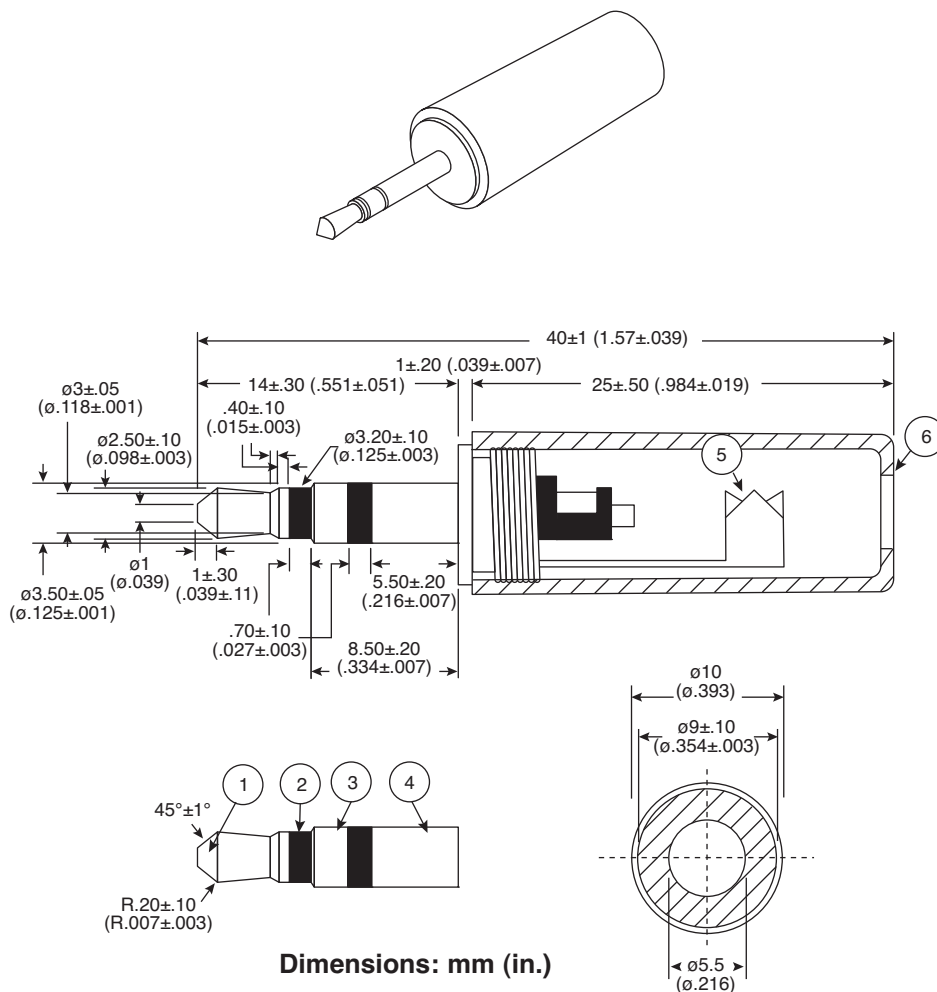

SPECIFICATIONS

Insulation Resistance:	100 M Ω min. @ 500VDC
Dielectric Strength:	500VAC for 1 min.

MATERIAL SPECIFICATIONS

Part Name	Material	Finish
1: Tip	Brass	Ni
2: Insulator	ABS, Black	
3 & 4: Sleeve	Brass	Ni
5: Sleeve Terminal	Brass	Ni
6: Cap	ABS, Black	

RoHS Compliant

Date Last Revised: 10-27-08

Available from Mouser Electronics
1-800-346-6873 / www.mouser.com

KC-301205

171-PA3291-1-E

Specifications are subject to change without notice. No liability or warranty implied by this information. Environmental compliance based on producer documentation.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Kobiconn:](#)

[171-PA3291-1-E](#)