
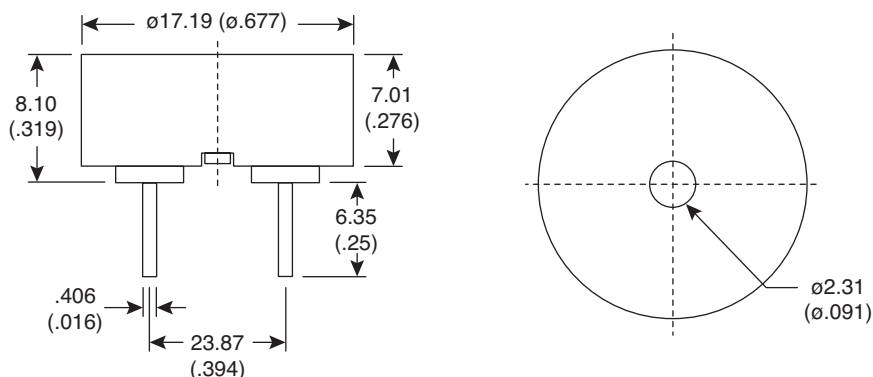


Part Number:

254-15240-ROX

Piezoelectric Buzzer (External Drive)

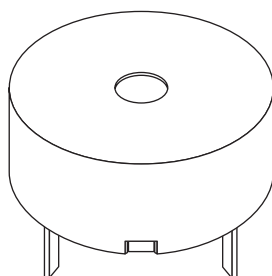

KT-400268

Electrical Specifications:

- Sound pressure level: 80dB min. @ 4,096Hz/9Vp-p, square wave/10cm; 70dB min. @ 4,096Hz/1Vrms, sine wave/10cm
- Capacitance: 10,000pF $\pm 30\%$ @ 120Hz 25°C
- Current consumption: 3mA max. @ 4,096Hz 9Vp-p square wave

Materials:

- Top case: PC
- Bottom case: PBTGF
- Pins: tin plated brass
- Weight: 1gm

Mechanical Specifications:

- Pin pitch: 10 \pm 3mm
- Operating temperature: -20°~+105°C

Note:

- RoHS Compliant by Exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-15240-ROX](#)