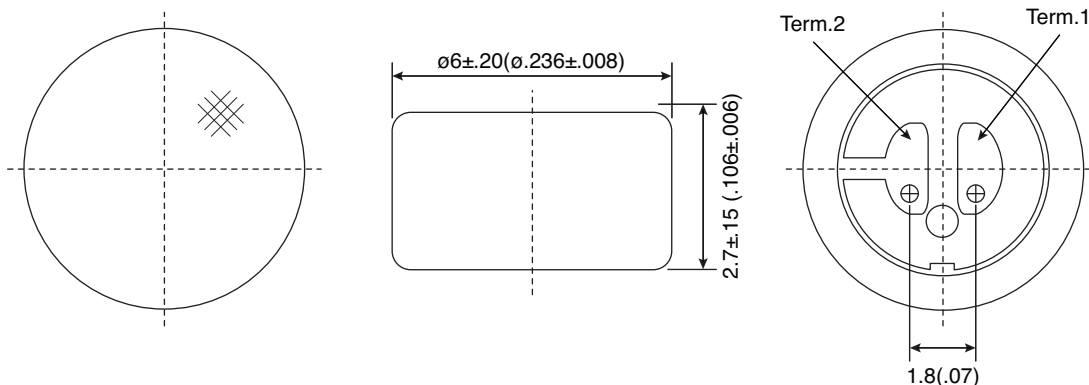
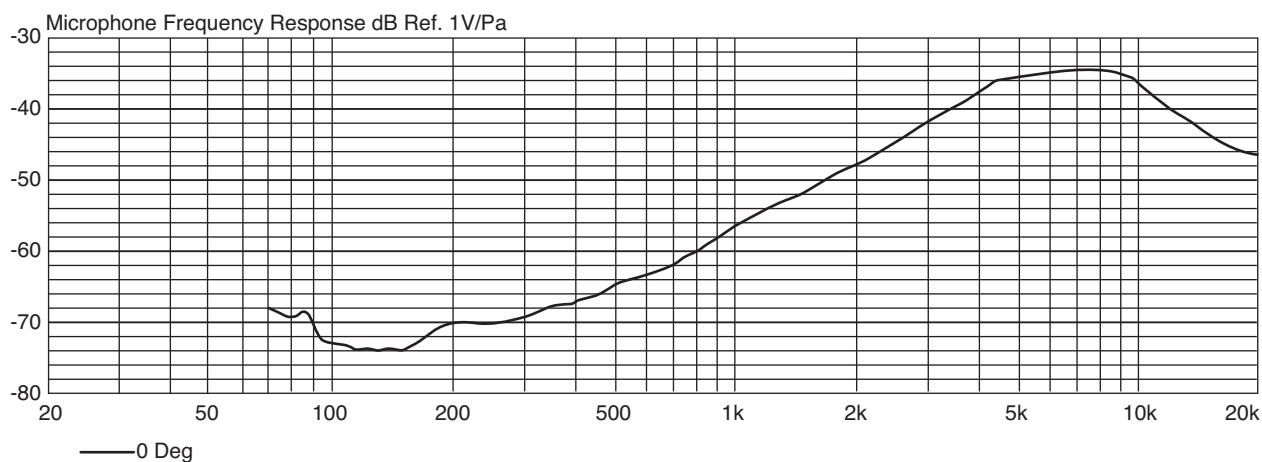


Part Number:

254-ECM61-RO


Frequency Response Curve


KT-400334

Electrical Specifications:

- Sensitivity: -51 ± 3 dB (0 dB = 1V/Pa, 1KHz)
- Output Impedance: $2.2 K\Omega$ (Max)
- Frequency Range: 70-20,000Hz
- Standard Operation Voltage: 2V
- Current Consumption: 0.5mA (Max)
- S/N Ratio: >50dB

Mechanical Specifications:

- Operating Temperature: -25°C to $+70^{\circ}\text{C}$
- Storage Temperature: -40°C to $+70^{\circ}\text{C}$

Note:

- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-ECM61-RO](#)