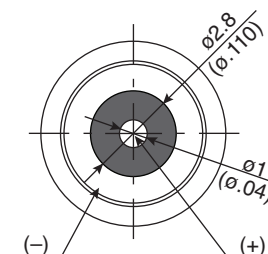
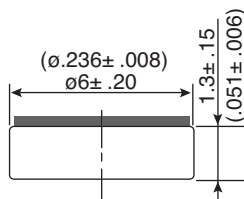
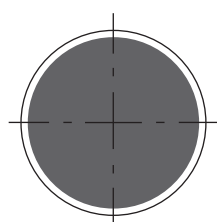
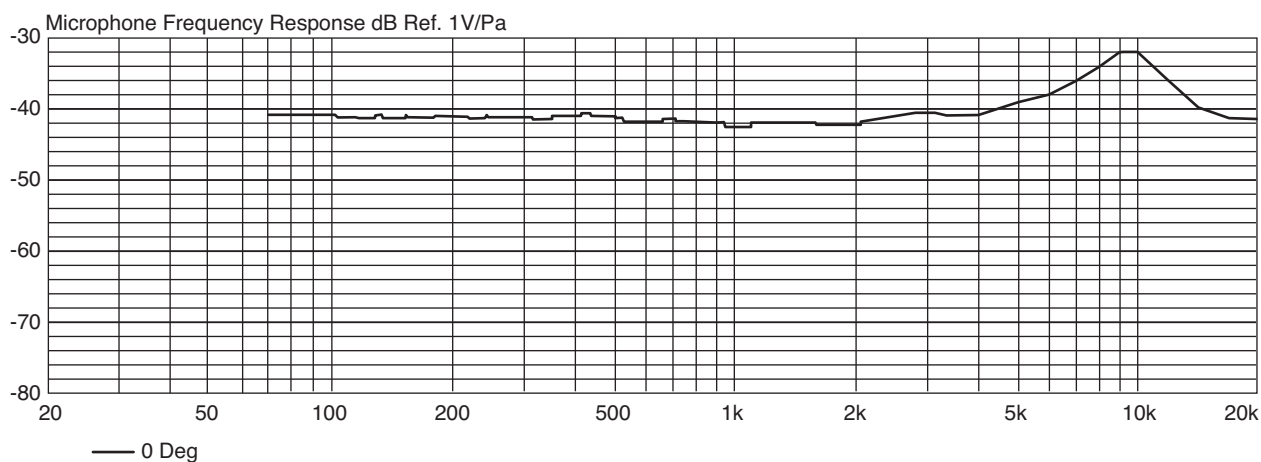


Part Number:

254-ECM602-RO


Frequency Response Curve


KT-400336

Electrical Specifications:

- Sensitivity: $-42 \pm 3\text{dB}$ ($0\text{dB}=1\text{V/Pa}$, 1KHz)
- Output Impedance: $2.2\text{K}\Omega(\text{Max})$
- Frequency Range: 70-20,000Hz
- Standard Operation Voltage: 2.0V
- Current Consumption: $0.5\text{mA}(\text{Max})$
- S/N Ratio: $> 58\text{dB}$

Mechanical Specifications:

- Operating temperature: $-25 \sim +70^{\circ}\text{C}$
- Storage temperature: $-40 \sim +70^{\circ}\text{C}$

Note:

- RoHS Compliant

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-ECM602-RO](#)