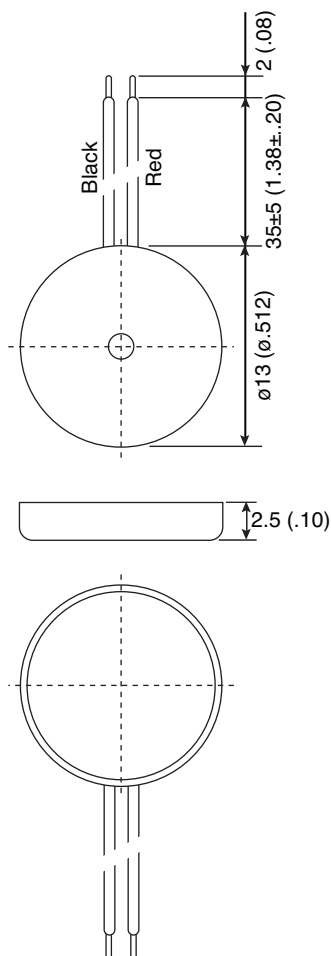
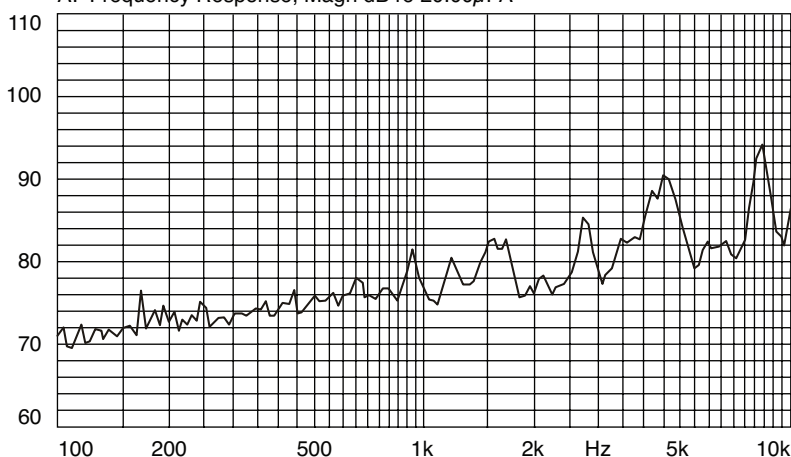


Part Number:

254-PB138-ROX

Piezoelectric Buzzer

A: Frequency Response, Magn dB re 20.00 μ PA

KT-400370

Electrical Specifications:

- Rated Voltage: 10 Vp-p
- Operating Voltage: 1~30 Vp-p
- Rated Current: 5mA(max)
- Sound Output At 10cm: 80dBA(min)
- Resonant Frequency: 4800Hz \pm 500
- Capacitance: 15000pF \pm 30% At 1KHz

Mechanical Specifications:

- Operating Temperature: -20°C ~ +70°C
- Storage Temperature: -30°C ~ +80°C

Note:

- RoHS Compliant by Exemption

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-PB138-ROX](#)