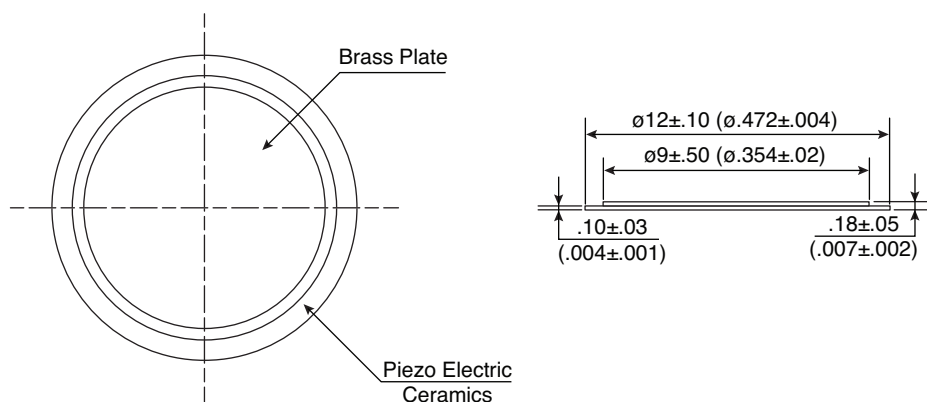


Part Number:

254-PB125-ROX

Dimensions: mm (in.)**Piezoelectric Buzzer Element**

KT-400449

Electrical Specifications:

- Resonant Frequency: 6.5K Hz \pm 0.6
- Resonant Impedance: 500 Ω (max.)
- Capacity: 13000pf \pm 30%
- Input Voltage: 30 Vp-p (max.)

Note:

- RoHS Compliant by exemption

Mechanical Specifications:

- Type: External drive
- Operating Temperature: -20°C ~ +60°C
- Storage Temperature: -20°C ~ +70°C

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Kobitone:

[254-PB125-ROX](#)