




Dimensions: mm (In)

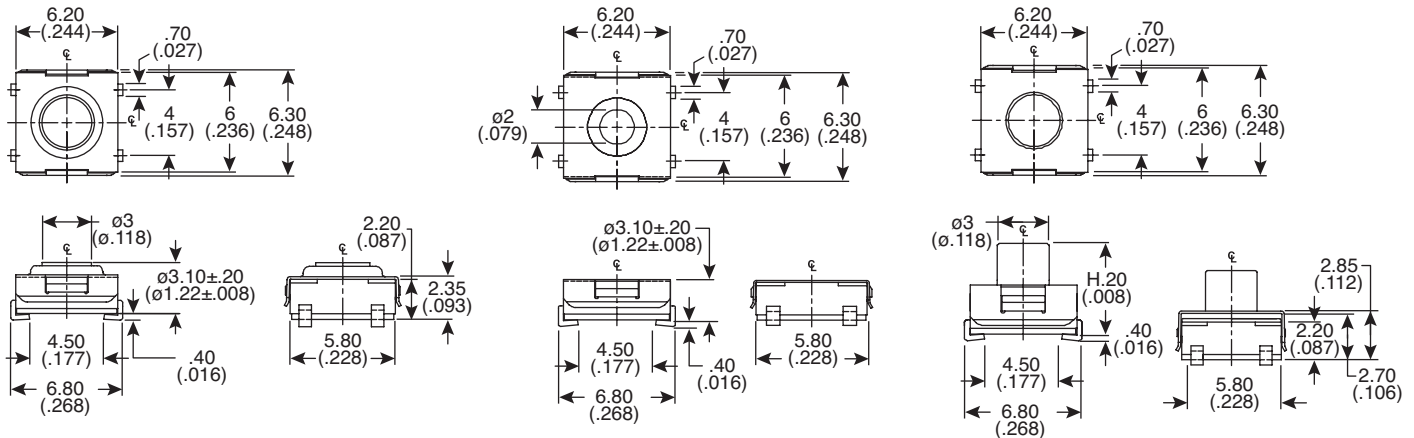

PCB Layout

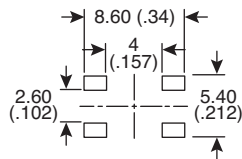

 Circuit Diagram



Electrical Specifications:

- Electrical Life:
 - 100K cycles (min.): 101-TS6923T1601-EV
 - 500K cycles (min.): 101-TS6923T1803-EV, 101-TS6923T1805-EV, 101-TS6923T2603-EV, 101-TS6923T2604-EV, 101-TS6923T2605-EV, 101-TS6923T3604-EV, 101-TS6923T3605-EV
- Rating: 50mA/12VDC
- Contact Resistance: 100m Ω max.
- Insulation Resistance: 100M Ω min. @ 500VDC
- Dielectric Strength: 250VAC/minute

Mechanical Specifications:

- Operating Force:
 - 160gf (silver): 101-TS6923T1601-EV
 - 180gf (brown): 101-TS6923T1803-EV, 101-TS6923T1805-EV
 - 260gf (red): 101-TS6923T2603-EV, 101-TS6923T2604-EV, 101-TS6923T2605-EV
 - 360gf (clear): 101-TS6923T3604-EV, 101-TS6923T3605-EV
- Stop Strength: Max 3kgf vertical static load cont. for 15 sec.
- Stroke:
 - 0.25 +0.20/-0.1mm: 101-TS6923T1601-EV
 - 0.45 $\pm$ 0.2mm: 101-TS6923T1803-EV, 101-TS6923T2603-EV, 101-TS6923T1805-EV, 101-TS6923T2605-EV, 101-TS6923T2604-EV
 - 0.6 $\pm$ 0.2mm: 101-TS6923T3604-EV, 101-TS6923T3605-EV
- Operating Temperature: -25°C to +70°C
- Storage Temperature: -30°C to +80°C
- Type: SPST

Note:

- RoHs Compliant and process compatible with 260° solder

Mouser Stock No.	H
101-TS6923T1601-EV	2.3mm
101-TS6923T1803-EV	3.5mm
101-TS6923T2603-EV	3.5mm
101-TS6923T2604-EV	3.8mm
101-TS6923T3604-EV	3.8mm
101-TS6923T1805-EV	5.2mm
101-TS6923T2605-EV	5.2mm
101-TS6923T3605-EV	5.2mm

Tactile Switches (SMT)

101-TS6923T1601-EV	101-TS6923T2604-EV	101-TS6923T2605-EV
101-TS6923T1803-EV	101-TS6923T3604-EV	101-TS6923T3605-EV
101-TS6923T2603-EV	101-TS6923T1805-EV	

Mountain Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[101-TS6923T1803-EV](#) [101-TS6923T1601-EV](#) [101-TS6923T3604-EV](#) [101-TS6923T2604-EV](#) [101-TS6923T3605-EV](#)
[101-TS6923T2605-EV](#) [101-TS6923T1805-EV](#) [101-TS6923T2603-EV](#)