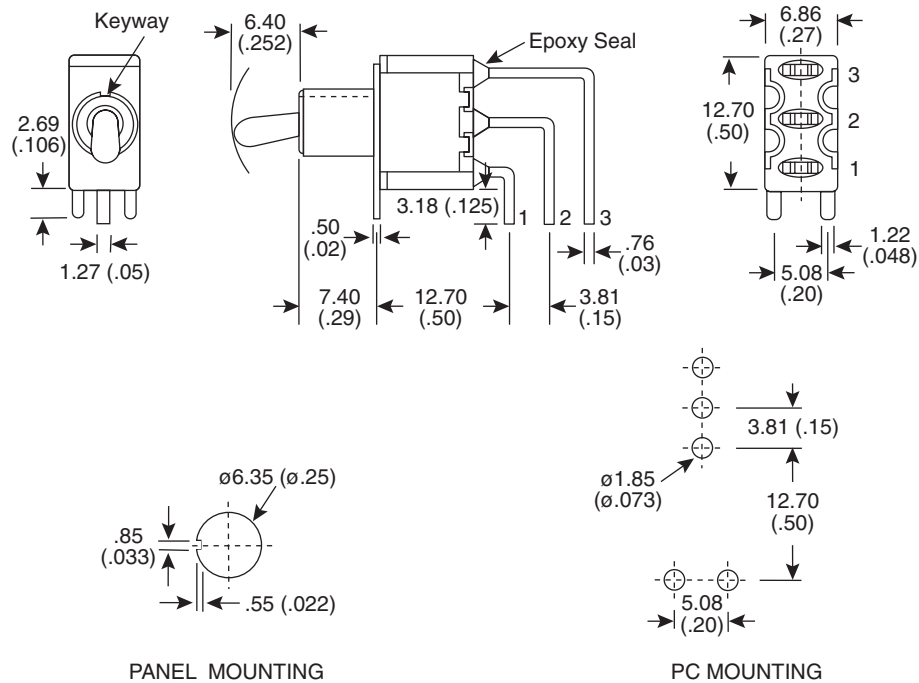


DIMENSIONS: mm (in.)

PANEL MOUNTING

PC MOUNTING

POS.1	POS.2	POS.3
ON	NONE	ON
2-3	N/A	2-1

SWITCH FUNCTION

Mechanical Specifications:

- Operating Temperature: -30°C to +85°C

Note:

- RoHS Compliant by Exemption

Electrical Specifications:

- Contact Resistance: 10mΩ max. initial @ 2-4VDC 100mA
- Insulation Resistance: 1,000MΩ min.
- Rating: 2A/ 250VAC, 5A/ 120VAC or 28VDC
- Dielectric Strength: 1,000 V RMS@ sea level

Materials:

- Case: Diallyl phthalate (DAP)
- Actuator: Brass, chrome plated
- Bushing: Brass, nickel plated
- Housing: Stainless steel
- Terminal/Contact: Silver plated

Toggle Switch
108-1MS1T2B4M7QE-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[108-1MS1T2B4M7QE-EVX](#)