


DIMENSIONS: mm (in.)

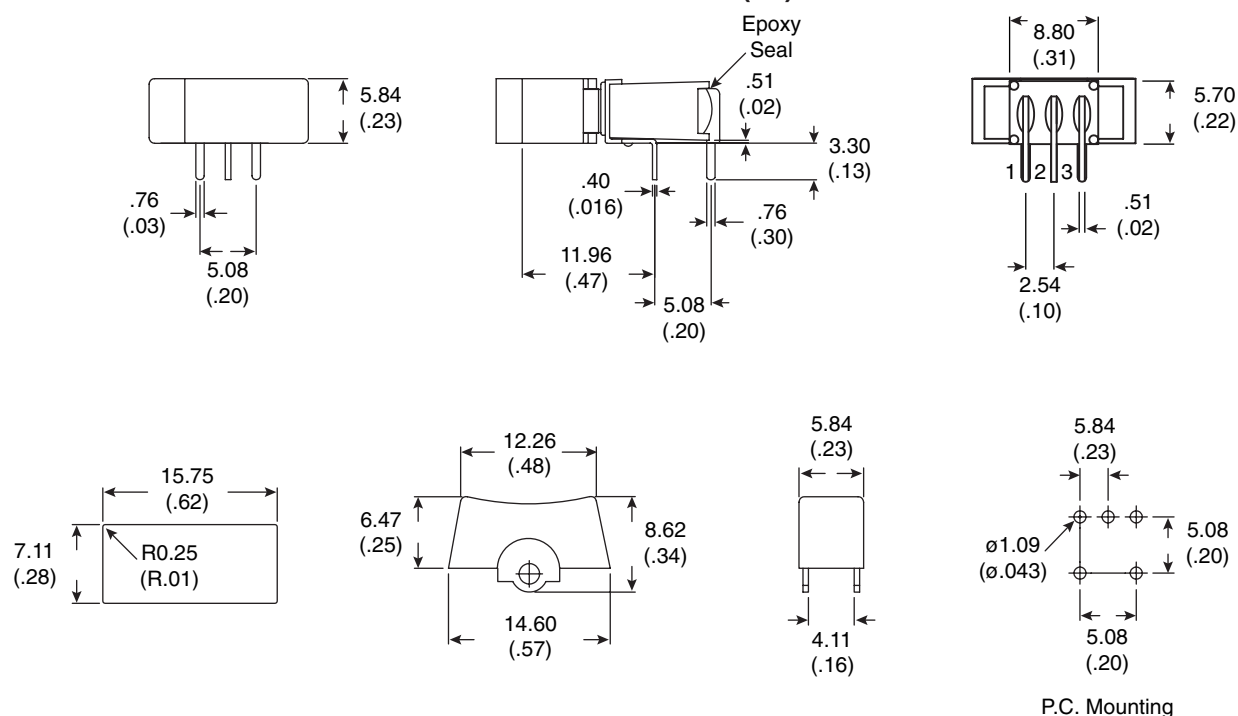

Pos. 1	Pos. 2	Pos. 3
On	None	On
2-3		2-1

Switch Function

Mechanical Specifications:

- Mechanical Life: 30,000 make-and-break cycles
- Operating Temperature: -30°C to 85°C

Electrical Specifications:

- Rating: 1A/250VAC, 3A/120VAC or 28 VDC
- Contact Resistance: 20mΩ max. initial @ 2-4 VDC 100mA
- Insulation Resistance: 1000MΩ min.
- Dielectric Strength: 1000 V RMS @ sea level

Materials:

- Case and Bushing: Glass filled nylon 6/6, flame retardant, heat stabilized
- Actuator: nylon, black std. internal o-ring seal standard with all actuators
- Switch Support: Brass or steel, tin plated
- Terminals/Contact: gold plated contact

Note:

- RoHS Compliant by exemption

Sealed Sub-Miniature Rocker Switch
103-7025-EVX

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-7025-EVX](#)