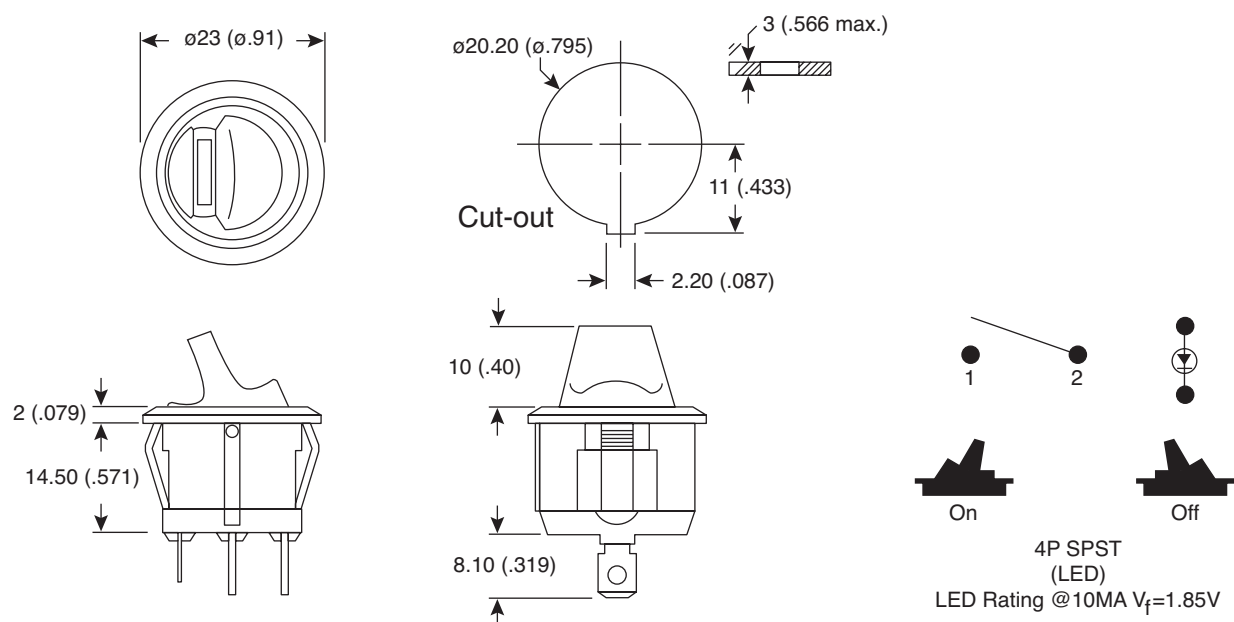


## Dimensions: mm (In.)

**Electrical Specifications:**

- Rating: 16A/125VAC, 10A/250VAC
- Contact resistance: 50m $\Omega$  max.
- Insulation resistance: 500VDC 100M $\Omega$  min.
- Dielectric strength: 1500VAC 1 minute

**Note:**

- RoHS Compliant

Mouser Stock No.	Color
103-R13-112LP-02R-EV	Red
103-R13-112LP-02Y-EV	Yellow
103-R13-112LP-02G-EV	Green

**Rocker Switches**

103-R13-112LP-02R-EV, 103-R13-112LP-02Y-EV,  
103-R13-112LP-02G-EV

**Mountain  
Switch**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[103-R13-112LP-02G-EV](#) [103-R13-112LP-02Y-EV](#) [103-R13-112LP-02R-EV](#)