


Dimensions: mm (in.)

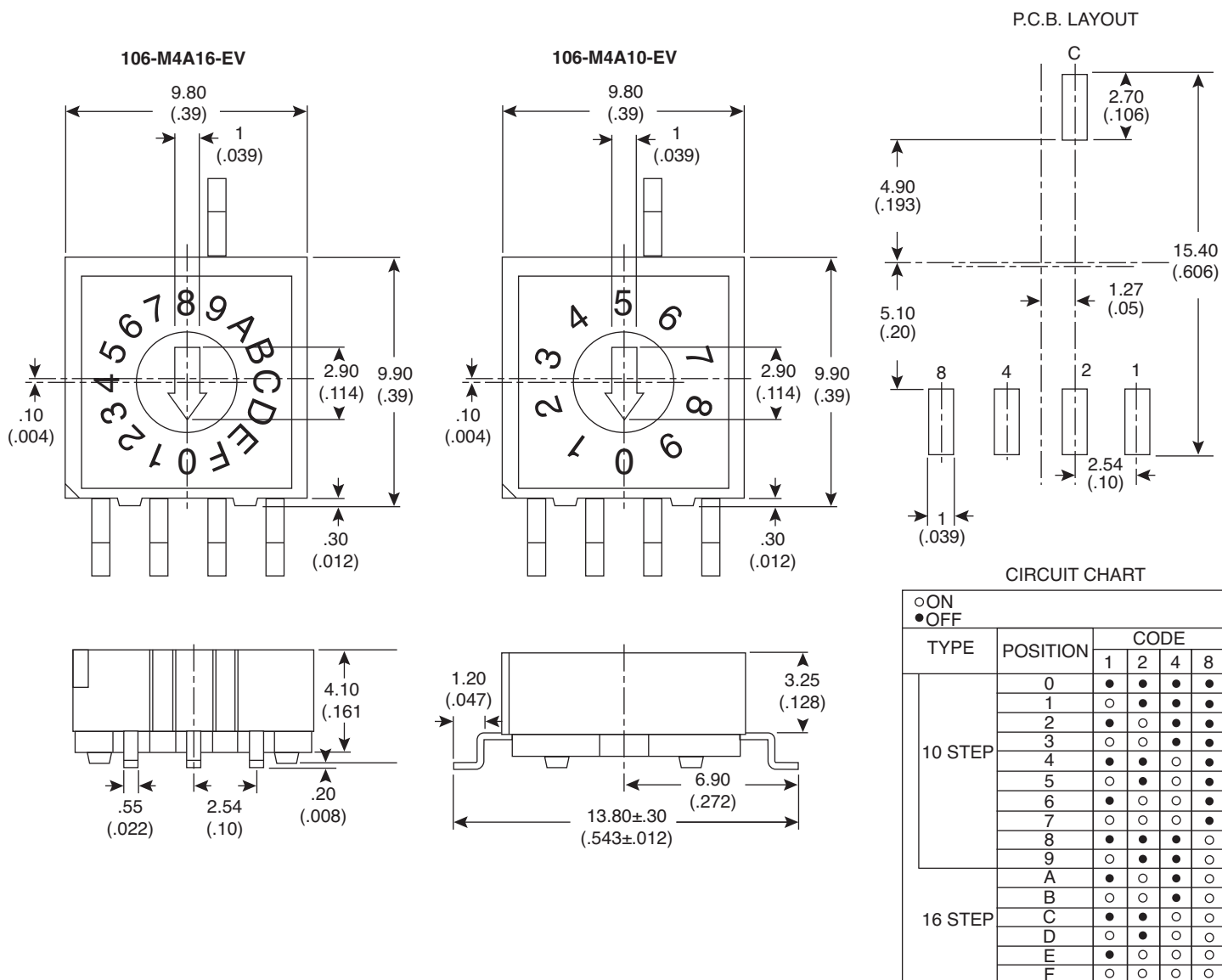

Electrical Specifications:

- Rating:
 - Non-Switching: 100mA/50V DC
 - Switching: 25mA/24V DC
- Contact Resistance: 100mΩ Max. (initial)
- Dielectric Strength: 250V AC for 1 min.
- Insulation Resistance: 100MΩ min. @ 250V DC

Mechanical Specifications:

- Operating Temperature: -25°C - +80°C
- Storage Temperature: -40°C - +85°C
- Operation Force: 200gf cm Max.

Note:

- RoHS Compliant

Rotary Dip Switches

106-M4A10-EV, 106-M4A16-EV

Mountain Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

[106-M4A10-EV](#) [106-M4A16-EV](#)