


Dimensions: mm (in.)

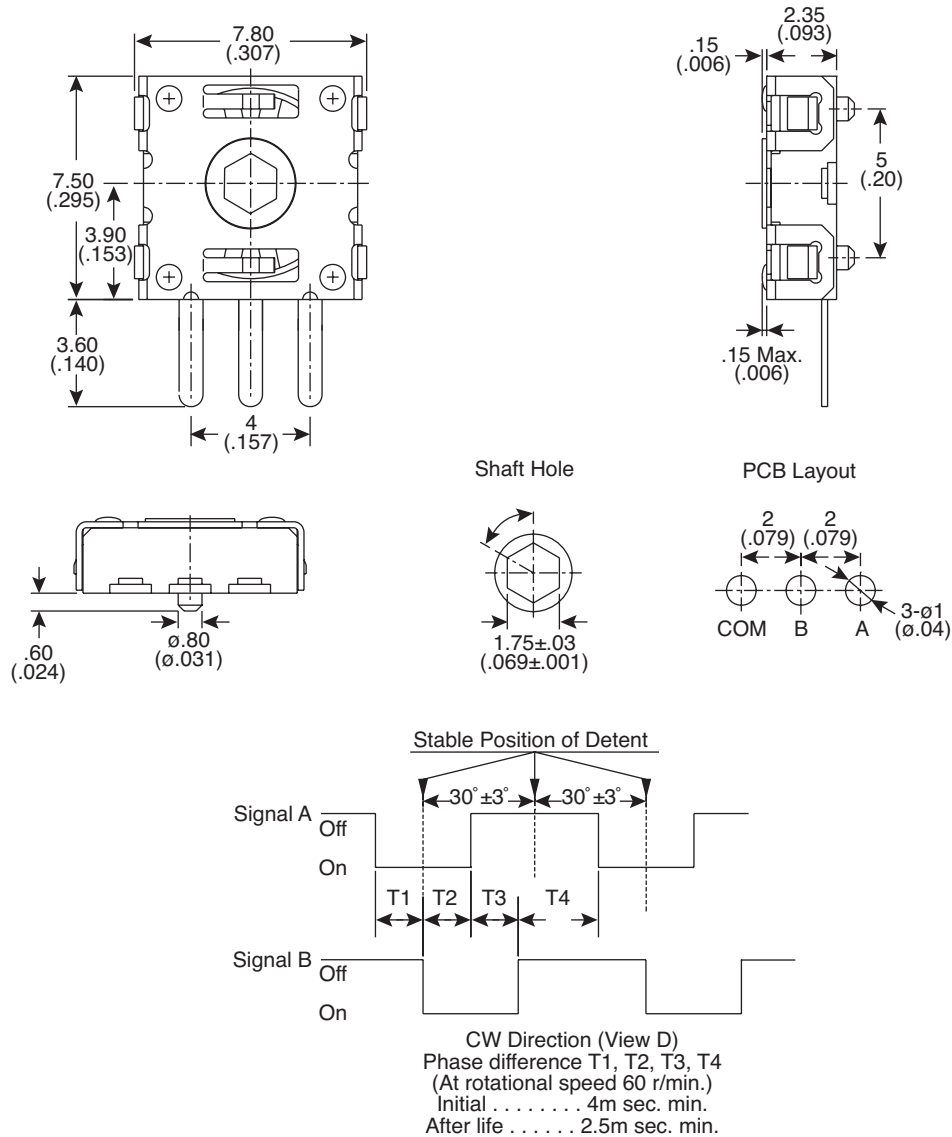

Electrical Specifications:

- Contact Rating: 1mA/10VDC
- Contact Resistance: $\leq 10\Omega$
- Isolation Resistance: $\geq 50M\Omega$ 50V DC
- Dielectric Strength: 50V AC 1 minute

Mechanical Specifications:

- Operating Force: $25 \pm 10gf$
- Operating Temperature: $-10^\circ C \sim +60^\circ C$
- Number and Positions of Segment Points: 12 Segment points (each segment angle: $30^\circ \pm 3^\circ$)
- Output Resolution: 6 pulse/360°

Note:

- RoHS Compliant

Encoder
101-5429-EV

Mountain
Switch

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Mountain Switch:

101-5429-EV